


LCD1U17-015/ 19-015 1U 17", 19" High Brightness Rackmount LCD Drawer

New



Diagram
Unit : mm

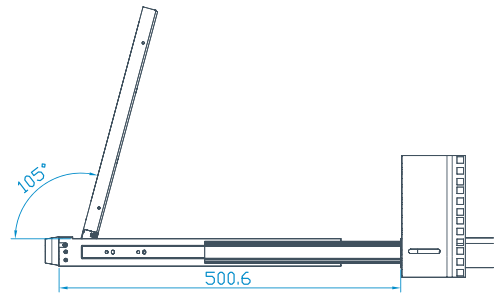

Options



BNC + S-Video



Touch Screen



Quad Display



DC Power



DVI-D



Audio

Drawer Features

- 1U rackmount LCD drawer with either 17" or 19" LCD
- "One Man" installation slides for easy, quick installation
- Enhanced aesthetics with new molded front panel and two point lock

LCD Drawer Benefits

- ▶ 800 cd/m² for 17", 19" LCD
- ▶ Low power consumption
- ▶ Long lifetime up to 70,000 hours
- ▶ Operation temperature at -20°C
- ▶ High shock & vibration resistance
- ▶ Slim size
- ▶ LED technology
- ▶ Minimum EMI emissions
- ▶ Mercury free

Optical Bonding Option



- 1mm thick optically clear adhesive for touchscreen or 4mm temper glass
- No air gap between the cover glass & LCD panel
- Increased LCD durability under vibration
- Eliminate residual and ghost images

Anti-Reflective Film Option



- 0.1mm thick optical interference coating film
- Designed to provide visual enhancement
- Cost effective vacuum laminated technology
- Greatly reduced specular & diffuse reflection
- Increased contrast for improved readability
- Easy clean surface

Ordering Information

	17" LCD	19" LCD
Model	LCD1U17-015	LCD1U19-015

Dimensions

Model	Product Dimension (W x D x H)	Net Weight
LCD1U17-015	442 x 600 x 44 mm 17.4 x 23.6 x 1.73 inch	12 kg / 26 lbs
LCD1U19-015	442 x 600 x 44 mm 17.4 x 23.6 x 1.73 inch	13 kg / 29 lbs