




**Toll Free : 1-888-865-6888**

**Tel : 510-226-8368 Fax : 510-226-8968**

**Email : [sales@RackmountMart.com](mailto:sales@RackmountMart.com)**

# Dual Rail -117 series

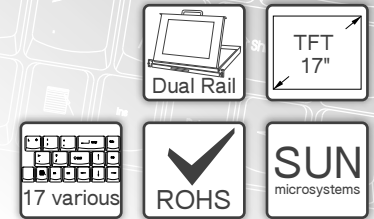


## 1U rack mount 17" TFT console

Dual Rail -117 series provide industrial level input solution to optimize your space utilization by controlling your system in just 1U rack space. With 11708 / 11716, you can control 8 / 16 platforms by using built-in KVM switch and easily expand the connections up to 8 levels with the combination of KVM switch boxes.


### Features

- Dual Rail for independent Panel and Keyboard tray
- Hidden handle for Keyboard tray
- Support Sun native resolution
- Support 17 various keyboard languages
- Bright Active Matrix TFT Display
- OSD function (On Screen Display) for LCD display
- Durable keyboards (touchpad or trackball)
- Panel protected by tempered glass
- Audio Function (optional)
- DC power (optional)

### Dimension

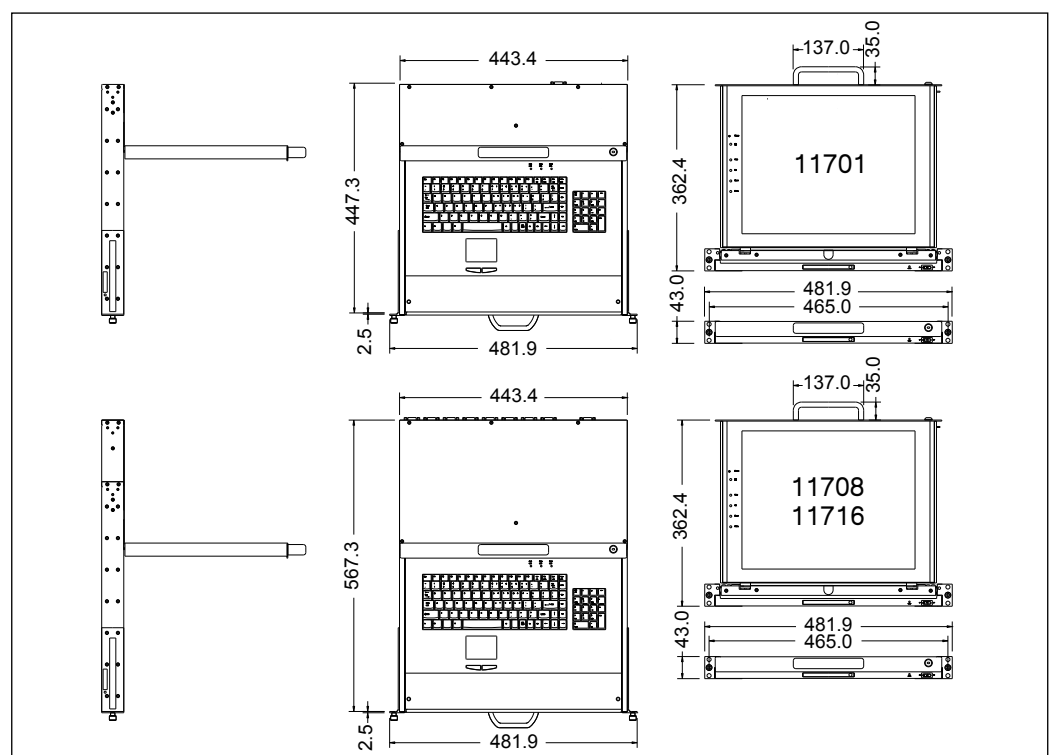

## Specification

 

<b>Model Name</b>	D-11701	D-11708	D-11716
<b>Number of ports</b>	1	8	16
<b>Dimension</b>	449.8x443.4x44 mm/17.7x17.5x1.7inches	569.8x443.4x44 mm/22.4x17.5x1.7 inches	569.8x443.4x44 mm/22.4x17.5x1.7 inches
<b>Package Dimension</b>	605x560x202 mm/23.8x22.0x8.0 inches	728x553x205 mm/28.7x21.8x8.1 inches	728x553x205 mm/28.7x21.8x8.1 inches
<b>Net Weight</b>	12.0 Kg / 26.5 lbs	13.0 Kg / 28.7 lbs	13.5 Kg / 29.8 lbs
<b>Gross Weight</b>	17.0 Kg / 37.5 lbs	19.5 Kg / 43.0 lbs	20.0 Kg / 44.1 lbs
<b>Display Size</b>	17 inches		
<b>Panel Type</b>	Active Matrix TFT LCD		
<b>Resolution Capabilities</b>	Maximum Resolution up to 1280 x 1024 (SXGA)		
<b>Pixel Pitch</b>	Supports 0.264 mm x 0.264 mm		
<b>Viewing Angle (CR&gt;10)</b>	Right-Left view 60°~70°(Typ) Up-Down View 45°~60°(Typ)		
<b>Contrast Ratio</b>	450 : 1		
<b>Brightness</b>	White 250 cd/m <sup>2</sup> (Center 1 point Typ)		
<b>Back Light</b>	Four Lamps for Back Light		
<b>Supported Colors</b>	16.2M Colors (6-bit with FRC)		
<b>Response Time</b>	Rising Time 2 ms, Decay Time 14 ms		
<b>Operating System</b>	Dos, Windows (3.1, 9x, 2000, NT4, ME, XP, 2003 Server) Linux, Novell 3.12-6, HP UX, SUN		
<b>Multi Platform</b>	Support PS/2 and USB		
<b>System Cables</b>	VGA + PS/2 x 2 cable or VGA + USB x 1 cable		
<b>Keyboard Mouse</b>	106 key PS/2 keyboard with touch pad		
<b>Sync</b>	45 ~ 80 KHz		
<b>Power Source</b>	100 ~ 240 VAC input		
<b>Power Consumption</b>	25 W, 19.05 W for Panel		
<b>Temperature</b>	Operate 0°~ 50°C / 32°~ 122°F Storage -20°~ 60°C / -4°~ 140°F		
<b>Humidity</b>	10% ~ 90% RH		
<b>Chassis Construction</b>	Heavy duty steel materials		
<b>Keyboard Language</b>	US, UK, German, French, Spanish, Italian, Portuguese, Dutch, Swiss, Belgium, Swedish, Norwegian, Danish, Japanese, Mandarin, Russian, Hebrew		
<b>Certification</b>	CE / FCC, UL / CUL / C-Tick		

## Ordering Optional

- Color (Black / Beige / OEM color)
- Cherry keyboard with trackball (PS/2 only)
- Touch screen (USB or RS232) (11701 only)
- DC power ( - 48V ~ + 48V with additional cost / + - 12V without additional cost)
- USB interface (11701 only)
- Additional SUN function key
- Rear bracket extension up to 1030mm
- Detachable keyboard plate
- Signal cable 1.8m / 3.0m / 5.0m
- Audio function (11701 only)
- DVI interface (11701 only)

## Diagram

