


LCD1U17-19/ 19-14 1U Rackmount High Bright LCD Keyboard/KVM Drawer




Diagram

Unit : mm

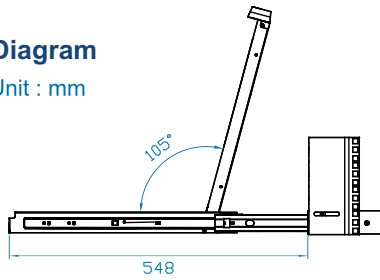

Dimensions

Model	Product Dimension (W x D x H)	Net Weight
LCD1U17-19	442 x 650 x 44 mm	16 kg / 35 lbs
LCD1U19-14	17.4 x 25.6 x 1.73 inch	

 

Options



BNC + S-Video

DVI-D

DC Power

Audio

Touch Screen (*the height changed from 1U to 1.5U*)

Drawer & KVM Features

- 1U keyboard LCD drawer with either 17" or 19" LCD
- Combo interface either PS/2 or USB input to the LCD drawer
- Mix PS/2, USB & SUN with Multi-Platform switch capability
- "One Man" installation slides for easy, quick installation
- Slide rails with fixed positions to prevent drawer movement when typing
- Enhanced aesthetics with new molded front panel and two point lock

LCD Drawer Benefits

- ▶ 800 cd/m² for 17", 19" LCD
- ▶ Low power consumption
- ▶ Long lifetime up to 70,000 hours
- ▶ Operation temperature at -20°C
- ▶ High shock & vibration resistance
- ▶ Minimum EMI emissions
- ▶ Mercury free
- ▶ Slim size

Optical Bonding Option



- 1mm thick optically clear adhesive for touchscreen or 4mm temper glass
- No air gap between the cover glass & LCD panel
- Increased LCD durability under vibration
- Eliminate residual and ghost images

Anti-Reflective Film Option








 



- 0.1mm thick optical interference coating film
- Designed to provide visual enhancement
- Cost effective vacuum laminated technology
- Greatly reduced specular & diffuse reflection
- Increased contrast for improved readability
- Easy clean surface

KVM Selection


 


Base Model	17" LCD Series	19" LCD Series
<ul style="list-style-type: none"> * Single port w/o KVM * Combo interface 	LCD1U17-19	LCD1U19-14




Combo Cat6 KVM

	1 console	Combo Cat6 8 port	LCD1U17-19-U8KVM	LCD1U19-14-U8KVM
	2 consoles		LCD1U17-19-U8KVM2	LCD1U19-14-U8KVM2
IP 	2 consoles		LCD1U17-19-U8KVM2IP	LCD1U19-14-U8KVM2IP
	1 console	Combo Cat6 16 port	LCD1U17-19-U16KVM	LCD1U19-14-U16KVM
	2 consoles		LCD1U17-19-U16KVM2	LCD1U19-14-U16KVM2
IP 	2 consoles		LCD1U17-19-U16KVM2IP	LCD1U19-14-U16KVM2IP
	1 console	Combo Cat6 32 port	LCD1U17-19-U32KVM	LCD1U19-14-U32KVM
	2 consoles		LCD1U17-19-U32KVM2	LCD1U19-14-U32KVM2
IP 	2 consoles		LCD1U17-19-U32KVM2IP	LCD1U19-14-U32KVM2IP

Combo DB-15 KVM

	1 console	Combo DB-15 8 port	LCD1U17-19-8KVM-u	LCD1U19-14-8KVM-u
	2 consoles		LCD1U17-19-8KVM2	LCD1U19-14-8KVM2
IP 	2 consoles		LCD1U17-19-8KVM2IP	LCD1U19-14-8KVM2IP
	1 console	Combo DB-15 16 port	LCD1U17-19-16KVM-u	LCD1U19-14-16KVM-u
	2 consoles		LCD1U17-19-16KVM2	LCD1U19-14-16KVM2
IP 	2 consoles		LCD1U17-19-16KVM2IP	LCD1U19-14-16KVM2IP

PS/2 DB-15 KVM



	1 console	 DB-15 8 port	LCD1U17-19-8KVM	LCD1U19-14-8KVM
			DB-15 16 port	LCD1U17-19-16KVM

Keyboard Selection

Supporting layouts



 104 Keys KB integrated with touchpad

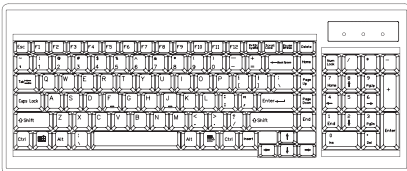

104 Keys KB integrated with trackball

