

LCD1U17-21 1U Dual Slide Rackmount SUN LCD Keyboard/KVM Drawer

New



Options



DVI-D



DC Power

DVI-D



DC Power




Dimensions

Model	Product Dimension (W x D x H)	Net Weight
LCD1U17-21	442 x 650 x 44 mm 17.4 x 25.6 x 1.73 inch	16 kg / 35 lbs

Diagram

Unit : mm

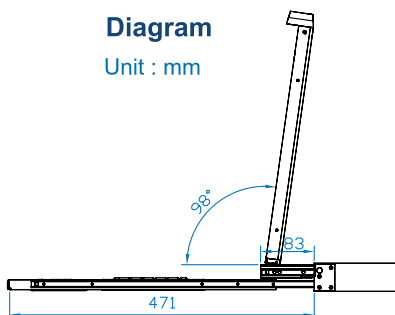

Drawer Features & Options

- Combo interface either PS/2 or USB input to the LCD drawer
- SUN key support including Stop, Cut, Paste, Compose etc
- US and UK keyboard language selections with touchpad
- Enhanced aesthetics with new molded front panel and two point lock

LCD Drawer & KVM Benefits

- ▶ 1U dual slide rackmount drawer with either 17" or 19" LCD
- ▶ Multi-user Matrix KVM with either 16 or 32 ports in 1U
- ▶ Cost efficient Combo KVM integration
- ▶ Direct support for SUN Micro 1152 x 900 native resolution
- ▶ Mix PS/2, USB & SUN with Multi-Platform switch capability
- ▶ Secure remote user access across the world wide web

Monitor Grade A 17", 19" industrial TFT LCD panel

- 17" 1280 x 1024 LCD with 300 nit brightness and 1000:1 contrast ratio typical
- 19" 1280 x 1024 LCD with 300 nit brightness and 1000:1 contrast ratio typical

 

Keyboard Selection

Supporting layouts



USB interface, Incorporates SUN keys

N 104 keyboard integrated with touchpad

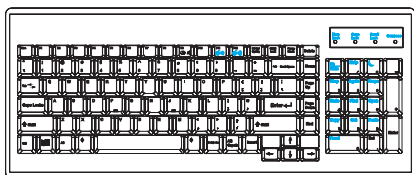

KVM Selection







Base Model







17" LCD Series

<ul style="list-style-type: none"> • Single port w/o KVM • USB interface 	LCD1U17-21
--	------------















Matrix Cat6 KVM

	2 consoles	Matrix Cat6 16 port	LCD1U17-21-MU162
	3 consoles		LCD1U17-21-MU163
	4 consoles		LCD1U17-21-MU164
IP 	3 consoles	Matrix IP Cat6 16 port	LCD1U17-21-MU163IP
IP 	4 consoles		LCD1U17-21-MU164IP
IP IP 	4 consoles		LCD1U17-21-MU164IP2










	2 consoles	Matrix Cat6 32 port	LCD1U17-21-MU322
	3 consoles		LCD1U17-21-MU323
	4 consoles		LCD1U17-21-MU324
IP 	3 consoles	Matrix IP Cat6 32 port	LCD1U17-21-MU323IP
IP 	4 consoles		LCD1U17-21-MU324IP
IP IP 	4 consoles		LCD1U17-21-MU324IP2

Matrix DB-15 KVM







	2 consoles	Matrix DB-15 8 port	LCD1U17-21-M82
	3 consoles		LCD1U17-21-M83
	4 consoles		LCD1U17-21-M84
IP 	3 consoles	Matrix IP DB-15 8 port	LCD1U17-21-M83IP
IP 	4 consoles		LCD1U17-21-M84IP
IP IP 	4 consoles		LCD1U17-21-M84IP2

	2 consoles	Matrix DB-15 16 port	LCD1U17-21-M162
	3 consoles		LCD1U17-21-M163
	4 consoles		LCD1U17-21-M164
IP 	3 consoles	Matrix IP DB-15 16 port	LCD1U17-21-M163IP
IP 	4 consoles		LCD1U17-21-M164IP
IP IP 	4 consoles		LCD1U17-21-M164IP2

Combo Cat6 KVM

	1 console	Combo Cat6 8 port	LCD1U17-21-U8KVM
	2 consoles		LCD1U17-21-U8KVM2
IP 	2 consoles		LCD1U17-21-U8KVM2IP
	1 console	Combo Cat6 16 port	LCD1U17-21-U16KVM
	2 consoles		LCD1U17-21-U16KVM2
IP 	2 consoles		LCD1U17-21-U16KVM2IP
	1 console	Combo Cat6 32 port	LCD1U17-21-U32KVM
	2 consoles		LCD1U17-21-U32KVM2
IP 	2 consoles		LCD1U17-21-U32KVM2IP

Combo DB-15 KVM

	1 console	Combo DB-15 8 port	LCD1U17-21-8KVM-u
	2 consoles		LCD1U17-21-8KVM2
IP 	2 consoles		LCD1U17-21-8KVM2IP
	1 console	Combo DB-15 16 port	LCD1U17-21-16KVM-u
	2 consoles		LCD1U17-21-16KVM2
IP 	2 consoles		LCD1U17-21-16KVM2IP