

LCD1U19-13 1U Rackmount 19" Widescreen SUN LCD Keyboard KVM Drawer



Dimensions

Model	Product Dimension (W x D x H)	Net Weight
LCD1U19-13	442 x 600 x 44 mm 17.4 x 23.6 x 1.73 inch	20 kg / 44 lbs



Options



DVI-D



DC Power

DVI-D




DC Power



Diagram

Unit : mm

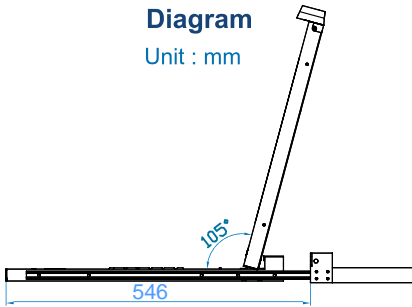

Drawer Features & Options

- 1U rackmount drawer with 19" widescreen LCD
- Combo interface either PS/2 or USB input to the LCD drawer
- SUN key support including Stop, Cut, Paste, Compose etc
- US and UK keyboard language selections with either touchpad or trackball
- Enhanced aesthetics with new molded front panel and two point lock

LCD Drawer & KVM Benefits

- ▶ Multi-user Matrix KVM with either 16 or 32 ports in 1U
- ▶ Cost efficient Combo KVM integration
- ▶ Direct support for SUN Micro 1152 x 900 native resolution
- ▶ 19" widescreen LCD with high resolution 1440 x 900
- ▶ Mix PS/2, USB & SUN with Multi-Platform switch capability
- ▶ Secure remote user access across the world wide web

 

Monitor Grade A Wide 19" industrial TFT LCD panel

- 19" 1440 x 900 LCD with 300 nit brightness and 1000:1 contrast ratio typical


Keyboard Selection

Supporting layouts USB interface, Incorporates SUN keys

Se NS keyboard integrated with touchpad

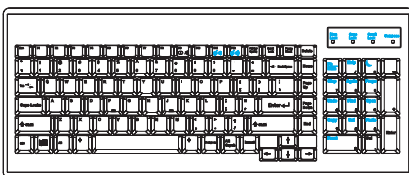

Sb NS keyboard integrated with trackball

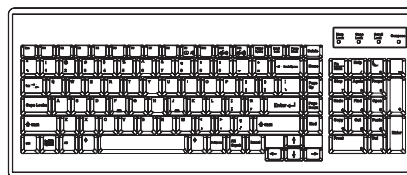

KVM Selection

Base Model

Wide 19" LCD Series



<ul style="list-style-type: none"> • Single port w/o KVM • USB interface 	<h2>LCD1U19-13</h2>
--	---------------------

Matrix Cat6 KVM

⚙️ ⚙️	2 consoles	Matrix Cat6 16 port	LCD1U19-13-MU162
⚙️ ⚙️ ⚙️	3 consoles		LCD1U19-13-MU163
⚙️ ⚙️ ⚙️ ⚙️	4 consoles		LCD1U19-13-MU164
IP ⚙️ ⚙️	3 consoles	Matrix IP Cat6 16 port	LCD1U19-13-MU163IP
IP ⚙️ ⚙️ ⚙️	4 consoles		LCD1U19-13-MU164IP
IP IP ⚙️ ⚙️	4 consoles		LCD1U19-13-MU164IP2
⚙️ ⚙️	2 consoles	Matrix Cat6 32 port	LCD1U19-13-MU322
⚙️ ⚙️ ⚙️	3 consoles		LCD1U19-13-MU323
⚙️ ⚙️ ⚙️ ⚙️	4 consoles		LCD1U19-13-MU324
IP ⚙️ ⚙️	3 consoles	Matrix IP Cat6 32 port	LCD1U19-13-MU323IP
IP ⚙️ ⚙️ ⚙️	4 consoles		LCD1U19-13-MU324IP
IP IP ⚙️ ⚙️	4 consoles		LCD1U19-13-MU324IP2

Matrix DB-15 KVM

⚙️ ⚙️	2 consoles	Matrix DB-15 8 port	LCD1U19-13-M82
⚙️ ⚙️ ⚙️	3 consoles		LCD1U19-13-M83
⚙️ ⚙️ ⚙️ ⚙️	4 consoles		LCD1U19-13-M84
IP ⚙️ ⚙️	3 consoles	Matrix IP DB-15 8 port	LCD1U19-13-M83IP
IP ⚙️ ⚙️ ⚙️	4 consoles		LCD1U19-13-M84IP
IP IP ⚙️ ⚙️	4 consoles		LCD1U19-13-M84IP2
⚙️ ⚙️	2 consoles	Matrix DB-15 16 port	LCD1U19-13-M162
⚙️ ⚙️ ⚙️	3 consoles		LCD1U19-13-M163
⚙️ ⚙️ ⚙️ ⚙️	4 consoles		LCD1U19-13-M164
IP ⚙️ ⚙️	3 consoles	Matrix IP DB-15 16 port	LCD1U19-13-M163IP
IP ⚙️ ⚙️ ⚙️	4 consoles		LCD1U19-13-M164IP
IP IP ⚙️ ⚙️	4 consoles		LCD1U19-13-M164IP2

Combo Cat6 KVM

⚙️	1 console	Combo Cat6 8 port	LCD1U19-13-U8KVM
⚙️ ⚙️	2 consoles		LCD1U19-13-U8KVM2
IP ⚙️	2 consoles		LCD1U19-13-U8KVM2IP
⚙️	1 console	Combo Cat6 16 port	LCD1U19-13-U16KVM
⚙️ ⚙️	2 consoles		LCD1U19-13-U16KVM2
IP ⚙️	2 consoles		LCD1U19-13-U16KVM2IP
⚙️	1 console	Combo Cat6 32 port	LCD1U19-13-U32KVM
⚙️ ⚙️	2 consoles		LCD1U19-13-U32KVM2
IP ⚙️	2 consoles		LCD1U19-13-U32KVM2IP

Combo DB-15 KVM

⚙️	1 console	Combo DB-15 8 port	LCD1U19-13-8KVM
⚙️ ⚙️	2 consoles		LCD1U19-13-8KVM2
IP ⚙️	2 consoles		LCD1U19-13-8KVM2IP
⚙️	1 console	Combo DB-15 16 port	LCD1U19-13-16KVM
⚙️ ⚙️	2 consoles		LCD1U19-13-16KVM2
IP ⚙️	2 consoles		LCD1U19-13-16KVM2IP