



LCD1U19-18

1U rack mount 19" TFT console


It is cost efficiency industrial level input solution, easy to install and use. It provides optimize your space utilization by controlling your system in just 1U rack space. **UL listed** and RoHS Compliant.



Features

- Single rail easy to install and use
- Support Sun native resolution
- Support 17 various keyboard languages
- Bright Active Matrix TFT display
- OSD function (On Screen Display) for LCD display
- Durable keyboards (touchpad or trackball)
- Panel protected by tempered glass
- Audio function (optional)
- DC power (optional)
- Support DVI (optional)


Application

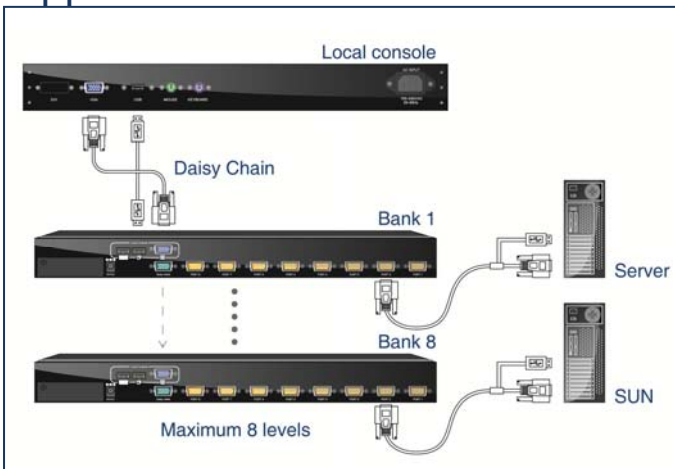

Specification

Model Name	LCD1U19-18-co
Number of ports	1
Dimension	532 x 447.5 x 44 mm / 20.9 x 17.6 x 1.7 inches
Package Dimension	715 x 564 x 206 mm / 28.1 x 22.2 x 8.1 inches
Net Weight	12.5 Kg / 27.6 lbs
Gross Weight	19.5 Kg / 43.0 lbs
Display Size	19 inches
Panel Type	Active Matrix TFT LCD
Resolution Capabilities	Maximum Resolution up to 1280 x 1024 (SXGA)
Pixel Pitch	Supports 0.098 mm x 0.294 mm
Viewing Angle (CR>10)	Right-Left view 140° (typical) Up-Down View 140° (typical)
Contrast Ratio	500 : 1
Brightness	White 250 cd/m ² (Center 1 point typical)
Back Light	Four Lamps for Back Light
Supported Colors	16.2M Colors (6-bit with FRC)
Response Time	Rising Time 2 ms, Decay Time 10 ms
Operating System	Dos, Windows (3.1, 9x, 2000, NT4, ME, XP, 2003 Server) Linux, Novell 3.12-6, HP UX, SUN
Multi Platform	Support PS/2 and USB
System Cables	VGA + PS/2 x 2 cable or VGA + USB x 1 cable
Keyboard Mouse	106 key PS/2 keyboard with touch pad
Sync	45 ~ 80 KHz
Power Source	100 ~ 240 VAC input
Power Consumption	25 W, 21.05 W for Panel
Temperature	Operate 0 ~ 50 °C / 32 ~ 122 °F Storage -20 ~ 60 °C / -4 ~ 140 °F
Humidity	10% ~ 90% RH
Chassis Construction	Heavy duty steel materials
Keyboard Language	US, UK, German, French, Spanish, Italian, Portuguese, Dutch, Swiss, Belgium, Swedish, Norwegian, Danish, Japanese, Mandarin, Russian, Hebrew

Dimension

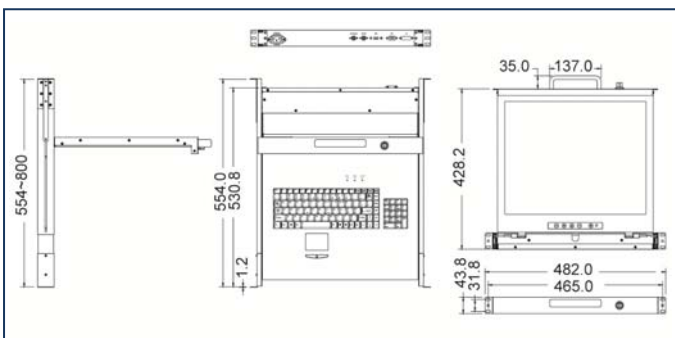

Ordering Optional

- Color (Black / Beige / OEM color)
- Cherry keyboard with trackball(PS/2 only)
- Touch screen (USB or RS232)
- DC power (- 48V ~ + 48V with additional cost / + - 12V with additional cost)
- Additional SUN function key
- Rear bracket extension up to 1030mm
- Signal cable 1.8 m / 3.0 m / 5.0 m (6 ft / 10 ft / 15 ft)
- Audio function
- DVI interface

SYNERGY GLOBAL TECHNOLOGY INC
Toll : 1-888-865-6888

Web : www.RackMountMart.com
Email : Sales.RackMountMart.com