



Toll : 1-888-865-6888

Tel : 510-226-8368

Fax : 510-226-8968

Sales@RackmountMart.com

LCD1U20-01

1U rack mount 20.1" TFT console

LCD1U20-01 provide industrial level input solution to optimize your space utilization by controlling your system in just 1U rack space.


Features

- Single Rail easy to install and use
- Support DVI signal input
- Support 17 various keyboard languages
- Bright Active Matrix TFT Display
- OSD function (On Screen Display) for LCD display
- Durable keyboards
- Panel protected by tempered glass
- Support USB K/B , touchpad (optional)
- Audio Function (optional)

DC power (optional)



Dimension and diagram

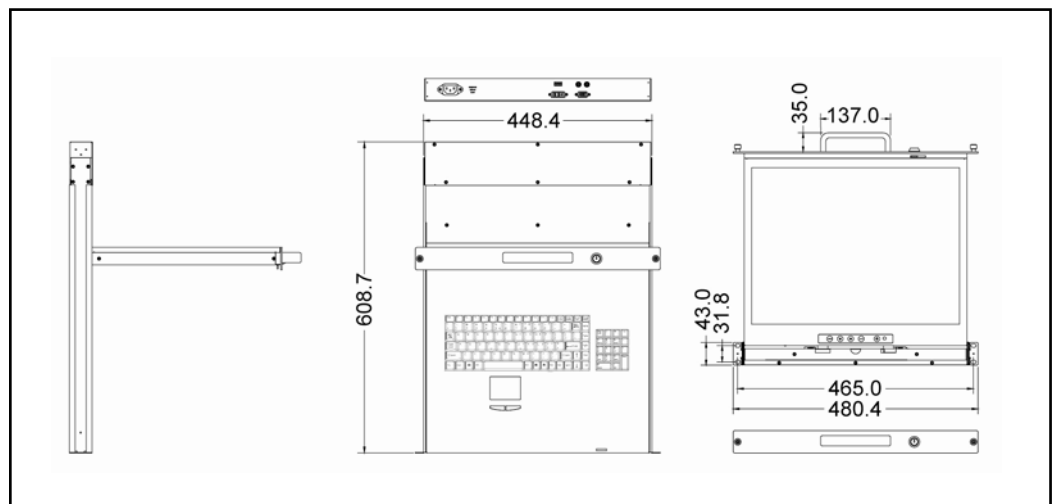

Specification

Model Name	LCD1U20-01
Number of ports	1
Dimension	448.7 x 608.4 x 44 mm / 17.7 x 24.0 x 1.7 inches
Package Dimension	564 x 838 x 206 mm / 22.2 x 33.0 x 8.1 inches
Net Weight	15.0 Kg / 33.1 lbs
Gross Weight	20.0 Kg / 44.1 lbs
Display Size	20.1 inches
Panel Type	Active Matrix TFT LCD
Resolution Capabilities	Maximum Resolution up to 1600 x 1200 (UXGA)
Pixel Pitch	Supports 0.255 mm x 0.255 mm
Viewing Angle (CR>10)	Right-Left view 85° (Typ) Up-Down View 85° (Typ)
Contrast Ratio	1000 : 1
Brightness	300 cd/m ²
Back Light	Six Lamps for Back Light
Supported Colors	16.7M Colors (RGB 8-bit data)
Response Time	Rising Time 15 ms, Falling Time 7 ms
Operating System	Dos, Windows (3.1, 9x, 2000, NT4, ME, XP, 2003 Server) Linux, Novell 3.12-6, HP UX, SUN
Multi Platform	Support PS/2 and USB
System Cables	VGA + PS/2 x 2 cable
Keyboard Mouse	106 key PS/2 keyboard with touch pad
Sync	45 ~ 80 KHz
Power Source	100 ~ 240 VAC input
Power Consumption	50W, 45W for Panel
Temperature	Operate 0 ~ 50 °C / 32 ~ 122 °F Storage -20 ~ 60 °C / -4 ~ 140 °F
Humidity	8 % ~ 95 % RH
Chassis Construction	Heavy duty steel materials
Keyboard Language	USA, UK, German, French, Spanish, Italian, Portuguese, Dutch, Swiss, Belgium, Swedish, Norwegian, Danish, Japan, Taiwan, Russian, Hebrew

Ordering Options

Color (Black / Beige / OEM color)
DC power (-48V ~ +48V with additional cost / +- 12V without additional cost)
USB type keyboard / mouse
Rear bracket extension up to 1030mm
Detachable keyboard plate
Signal cable 1.8m / 3.0m / 5.0m
Audio function