

# LCD1U20-02 1U 20" Rackmount LCD Keyboard KVM Drawer



## Dimensions

Model	Product Dimension (W x D x H)	Net Weight
LCD1U20-02	442 x 650 x 44 mm 17.4 x 25.6 x 1.73 inch	20 kg / 44 lbs



## Options



BNC + S-Video



DVI-D




DC Power




Audio

## Diagram


Unit : mm

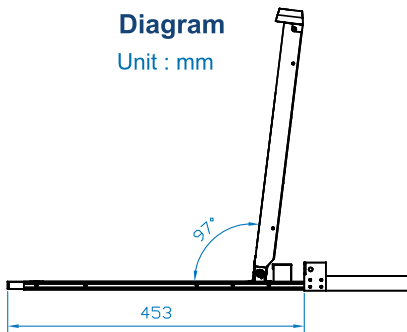

### BNC + S-Video

 

### DC Power

 

### DVI-D



### Audio



## Drawer Features & Options

- 1U rackmount drawer with 20" LCD
- Combo interface either PS/2 or USB input to the LCD drawer
- Multiple keyboard language selections with membrane mouse pad
- Enhanced aesthetics with new molded front panel and two point lock

## LCD Drawer & KVM Benefits

- ▶ Multi-user Matrix KVM with either 16 or 32 ports in 1U
- ▶ Cost efficient Combo KVM integration
- ▶ Ultra high resolution 1600 x 1200
- ▶ Mix PS/2, USB & SUN with Multi-Platform switch capability

**Monitor** LG Grade A 20" industrial TFT LCD panel


- 20" 1600 x 1200 LCD with 300 nit brightness and 800:1 contrast ratio typical

## Keyboard Selection

Supporting layouts



**N** N keyboard with full numerical pad

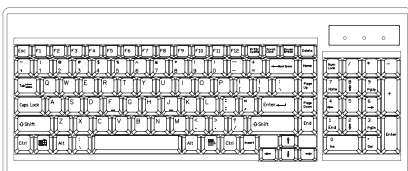

# KVM Selection







Base Model







20" LCD Series

<ul style="list-style-type: none"> <li>• Single port w/o KVM</li> <li>• Combo interface</li> </ul>	LCD1U20-02
--	------------















## Matrix Cat6 KVM

	2 consoles	<b>Matrix</b> Cat6 16 port	LCD1U20-02-MU162
	3 consoles		LCD1U20-02-MU163
	4 consoles		LCD1U20-02-MU164
<b>IP</b> 	3 consoles	<b>Matrix IP</b> Cat6 16 port	LCD1U20-02-MU163IP
<b>IP</b> 	4 consoles		LCD1U20-02-MU164IP
<b>IP IP</b> 	4 consoles		LCD1U20-02-MU164IP2









	2 consoles	<b>Matrix</b> Cat6 32 port	LCD1U20-02-MU322
	3 consoles		LCD1U20-02-MU323
	4 consoles		LCD1U20-02-MU324
<b>IP</b> 	3 consoles	<b>Matrix IP</b> Cat6 32 port	LCD1U20-02-MU323IP
<b>IP</b> 	4 consoles		LCD1U20-02-MU324IP
<b>IP IP</b> 	4 consoles		LCD1U20-02-MU324IP2

## Matrix DB-15 KVM






 
	2 consoles	<b>Matrix</b> DB-15 8 port	LCD1U20-02-M82
	3 consoles		LCD1U20-02-M83
	4 consoles		LCD1U20-02-M84
<b>IP</b> 	3 consoles	<b>Matrix IP</b> DB-15 8 port	LCD1U20-02-M83IP
<b>IP</b> 	4 consoles		LCD1U20-02-M84IP
<b>IP IP</b> 	4 consoles		LCD1U20-02-M84IP2

	2 consoles	<b>Matrix</b> DB-15 16 port	LCD1U20-02-M162
	3 consoles		LCD1U20-02-M163
	4 consoles		LCD1U20-02-M164
<b>IP</b> 	3 consoles	<b>Matrix IP</b> DB-15 16 port	LCD1U20-02-M163IP
<b>IP</b> 	4 consoles		LCD1U20-02-M164IP
<b>IP IP</b> 	4 consoles		LCD1U20-02-M164IP2



## Combo Cat6 KVM

	1 console	<b>Combo</b> Cat6 8 port	LCD1U20-02-U8KVM
	2 consoles		LCD1U20-02-U8KVM2
<b>IP</b> 	2 consoles		LCD1U20-02-U8KVM2IP
	1 console	<b>Combo</b> Cat6 16 port	LCD1U20-02-U16KVM
	2 consoles		LCD1U20-02-U16KVM2
<b>IP</b> 	2 consoles		LCD1U20-02-U16KVM2IP
	1 console	<b>Combo</b> Cat6 32 port	LCD1U20-02-U32KVM
	2 consoles		LCD1U20-02-U32KVM2
<b>IP</b> 	2 consoles		LCD1U20-02-U32KVM2IP

## Combo DB-15 KVM

	1 console	<b>Combo</b> DB-15 8 port	LCD1U20-02-8KVM-u
	2 consoles		LCD1U20-02-8KVM2
<b>IP</b> 	2 consoles		LCD1U20-02-8KVM2IP
	1 console	<b>Combo</b> DB-15 16 port	LCD1U20-02-16KVM-u
	2 consoles		LCD1U20-02-16KVM2
<b>IP</b> 	2 consoles		LCD1U20-02-16KVM2IP

## PS/2 DB-15 KVM

	1 console	 DB-15 8 port	LCD1U20-02-8KVM
			16 port