

LCD1U20-03 1U 20" Rackmount SUN LCD Keyboard KVM Drawer



Dimensions

Model	Product Dimension (W x D x H)	Net Weight
LCD1U20-03 Series	442 x 650 x 44 mm 17.4 x 25.6 x 1.73 inch	20 kg / 44 lbs



Options



DVI-D



DC Power


DVI-D



DC Power



Diagram
Unit : mm

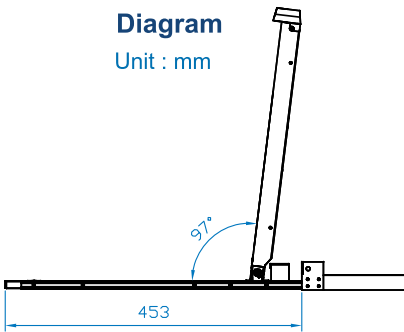

Drawer Features & Options

- 1U rackmount drawer with 20" LCD
- Combo interface either PS/2 or USB input to the LCD drawer
- SUN key support including Stop, Cut, Paste, Compose etc
- US and UK keyboard language selections with touchpad
- Enhanced aesthetics with new molded front panel and two point lock

LCD Drawer & KVM Benefits

- ▶ Multi-user Matrix KVM with either 16 or 32 ports in 1U
- ▶ Cost efficient Combo KVM integration
- ▶ Direct support for SUN Micro 1152 x 900 native resolution
- ▶ Ultra high resolution 1600 x 1200
- ▶ Mix PS/2, USB & SUN with Multi-Platform switch capability
- ▶ Secure remote user access across the world wide web


Monitor LG Grade A 20" industrial TFT LCD panel

- 20" 1600 x 1200 LCD with 300 nit brightness and 800:1 contrast ratio typical

Keyboard Selection

Supporting layouts USB interface, Incorporates SUN keys

Sn Sn keyboard with full numerical pad and SUN function

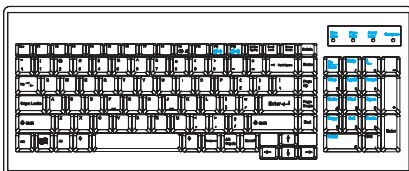

KVM Selection

Base Model

20" LCD Series

<ul style="list-style-type: none"> • Single port w/o KVM • USB interface 	LCD1U20-03
--	------------



Matrix Cat6 KVM

	2 consoles	Matrix Cat6 16 port	LCD1U20-03-MU162
	3 consoles		LCD1U20-03-MU163
	4 consoles		LCD1U20-03-MU164
IP	3 consoles	Matrix IP Cat6 16 port	LCD1U20-03-MU163IP
IP	4 consoles		LCD1U20-03-MU164IP
IP IP	4 consoles		LCD1U20-03-MU164IP2

	2 consoles	Matrix Cat6 32 port	LCD1U20-03-MU322
	3 consoles		LCD1U20-03-MU323
	4 consoles		LCD1U20-03-MU324
IP	3 consoles	Matrix IP Cat6 32 port	LCD1U20-03-MU323IP
IP	4 consoles		LCD1U20-03-MU324IP
IP IP	4 consoles		LCD1U20-03-MU324IP2

Matrix DB-15 KVM

	2 consoles	Matrix DB-15 8 port	LCD1U20-03-M82
	3 consoles		LCD1U20-03-M83
	4 consoles		LCD1U20-03-M84
IP	3 consoles	Matrix IP DB-15 8 port	LCD1U20-03-M83IP
IP	4 consoles		LCD1U20-03-M84IP
IP IP	4 consoles		LCD1U20-03-M84IP2

	2 consoles	Matrix DB-15 16 port	LCD1U20-03-M162
	3 consoles		LCD1U20-03-M163
	4 consoles		LCD1U20-03-M164
IP	3 consoles	Matrix IP DB-15 16 port	LCD1U20-03-M163IP
IP	4 consoles		LCD1U20-03-M164IP
IP IP	4 consoles		LCD1U20-03-M164IP2

Combo Cat6 KVM

	1 console	Combo Cat6 8 port	LCD1U20-03-U8KVM
	2 consoles		LCD1U20-03-U8KVM2
IP	2 consoles		LCD1U20-03-U8KVM2IP
	1 console	Combo Cat6 16 port	LCD1U20-03-U16KVM
	2 consoles		LCD1U20-03-U16KVM2
IP	2 consoles		LCD1U20-03-U16KVM2IP
	1 console	Combo Cat6 32 port	LCD1U20-03-U32KVM
	2 consoles		LCD1U20-03-U32KVM2
IP	2 consoles		LCD1U20-03-U32KVM2IP

Combo DB-15 KVM

	1 console	Combo DB-15 8 port	LCD1U20-03-8KVM
	2 consoles		LCD1U20-03-8KVM2
IP	2 consoles		LCD1U20-03-8KVM2IP
	1 console	Combo DB-15 16 port	LCD1U20-03-16KVM
	2 consoles		LCD1U20-03-16KVM2
IP	2 consoles		LCD1U20-03-16KVM2IP