

LCD2U17-04/ 19-03 2U Rackmount Dual Slide SUN LCD Keyboard/KVM Drawer



Options



DVI-D



DC Power

DVI-D




DC Power



Dimensions

Model	Product Dimension (W x D x H)	Net Weight
LCD2U17-04/19-03	442 x 600 x 88 mm 17.4 x 23.6 x 3.5 inch	18 kg / 40 lbs

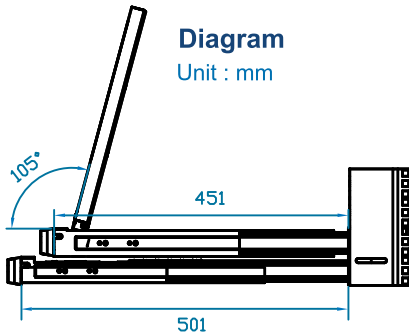

Drawer Features & Options

- Combo interface either PS/2 or USB input to the LCD drawer
- SUN key support including Stop, Cut, Paste, Compose etc
- US and UK keyboard language selections with either touchpad or trackball
- Slide rails with fixed positions to prevent drawer movement when typing
- Enhanced aesthetics with new molded front panel and two point lock

LCD Drawer & KVM Benefits

- ▶ 2U dual slide rackmount drawer with either 17" or 19" LCD
- ▶ Direct support for SUN Micro 1152 x 900 native resolution
- ▶ Multi-user Matrix KVM with either 16 or 32 ports in 2U
- ▶ Cost efficient Combo KVM integration
- ▶ Mix PS/2, USB & SUN with Multi-Platform switch capability
- ▶ Secure remote user access across the world wide web
- ▶ "One Man" installation slides for easy, quick installation

 

Monitor Grade A 17", 19" industrial TFT LCD panel

- 17" 1280 x 1024 LCD with 300 nit brightness and 1000:1 contrast ratio typical
- 19" 1280 x 1024 LCD with 300 nit brightness and 1000:1 contrast ratio typical


Keyboard Selection

Supporting layouts USB interface, Incorporates SUN keys

N 104 keyboard integrated with touchpad

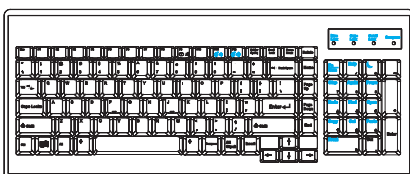

B 104 keyboard integrated with trackball

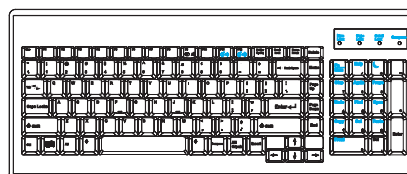

KVM Selection

Base Model







17" LCD Series







19" LCD Series








 
<ul style="list-style-type: none"> * Single port w/o KVM * USB interface 	LCD2U17-04	LCD2U19-03
--	------------	------------






 
Matrix Cat6 KVM

	2 consoles	Matrix Cat6 16 port	LCD2U17-04-MU162	LCD2U19-03-MU162
	3 consoles		LCD2U17-04-MU163	LCD2U19-03-MU163
	4 consoles		LCD2U17-04-MU164	LCD2U19-03-MU164
IP 	3 consoles	Matrix IP Cat6 16 port	LCD2U17-04-MU163IP	LCD2U19-03-MU163IP
IP 	4 consoles		LCD2U17-04-MU164IP	LCD2U19-03-MU164IP
IP IP 	4 consoles		LCD2U17-04-MU164IP2	LCD2U19-03-MU164IP2










	2 consoles	Matrix Cat6 32 port	LCD2U17-04-MU322	LCD2U19-03-MU322
	3 consoles		LCD2U17-04-MU323	LCD2U19-03-MU323
	4 consoles		LCD2U17-04-MU324	LCD2U19-03-MU324
IP 	3 consoles	Matrix IP Cat6 32 port	LCD2U17-04-MU323IP	LCD2U19-03-MU323IP
IP 	4 consoles		LCD2U17-04-MU324IP	LCD2U19-03-MU324IP
IP IP 	4 consoles		LCD2U17-04-MU324IP2	LCD2U19-03-MU324IP2

 Matrix DB-15 KVM







	2 consoles	Matrix DB-15 8 port	LCD2U17-04-M82	LCD2U19-03-M82
	3 consoles		LCD2U17-04-M83	LCD2U19-03-M83
	4 consoles		LCD2U17-04-M84	LCD2U19-03-M84
IP 	3 consoles	Matrix IP DB-15 8 port	LCD2U17-04-M83IP	LCD2U19-03-M83IP
IP 	4 consoles		LCD2U17-04-M84IP	LCD2U19-03-M84IP
IP IP 	4 consoles		LCD2U17-04-M84IP2	LCD2U19-03-M84IP2

	2 consoles	Matrix DB-15 16 port	LCD2U17-04-M162	LCD2U19-03-M162
	3 consoles		LCD2U17-04-M163	LCD2U19-03-M163
	4 consoles		LCD2U17-04-M164	LCD2U19-03-M164
IP 	3 consoles	Matrix IP DB-15 16 port	LCD2U17-04-M163IP	LCD2U19-03-M163IP
IP 	4 consoles		LCD2U17-04-M164IP	LCD2U19-03-M164IP
IP IP 	4 consoles		LCD2U17-04-M164IP2	LCD2U19-03-M164IP2

Combo Cat6 KVM

	1 console	Combo Cat6 8 port	LCD2U17-04-U8KVM	LCD2U19-03-U8KVM
	2 consoles		LCD2U17-04-U8KVM2	LCD2U19-03-U8KVM2
IP 	2 consoles		LCD2U17-04-U8KVM2IP	LCD2U19-03-U8KVM2IP
	1 console	Combo Cat6 16 port	LCD2U17-04-U16KVM	LCD2U19-03-U16KVM
	2 consoles		LCD2U17-04-U16KVM2	LCD2U19-03-U16KVM2
IP 	2 consoles		LCD2U17-04-U16KVM2IP	LCD2U19-03-U16KVM2IP
	1 console	Combo Cat6 32 port	LCD2U17-04-U32KVM	LCD2U19-03-U32KVM
	2 consoles		LCD2U17-04-U32KVM2	LCD2U19-03-U32KVM2
IP 	2 consoles		LCD2U17-04-U32KVM2IP	LCD2U19-03-U32KVM2IP

Combo DB-15 KVM

	1 console	Combo DB-15 8 port	LCD2U17-04-8KVM-u	LCD2U19-03-8KVM-u
	2 consoles		LCD2U17-04-8KVM2	LCD2U19-03-8KVM2
IP 	2 consoles		LCD2U17-04-8KVM2IP	LCD2U19-03-8KVM2IP
	1 console	Combo DB-15 16 port	LCD2U17-04-16KVM-u	LCD2U19-03-16KVM-u
	2 consoles		LCD2U17-04-16KVM2	LCD2U19-03-16KVM2
IP 	2 consoles		LCD2U17-04-16KVM2IP	LCD2U19-03-16KVM2IP