


# LCD2U20-011 2U LCD Rackmount LCD Drawer



Flip up design

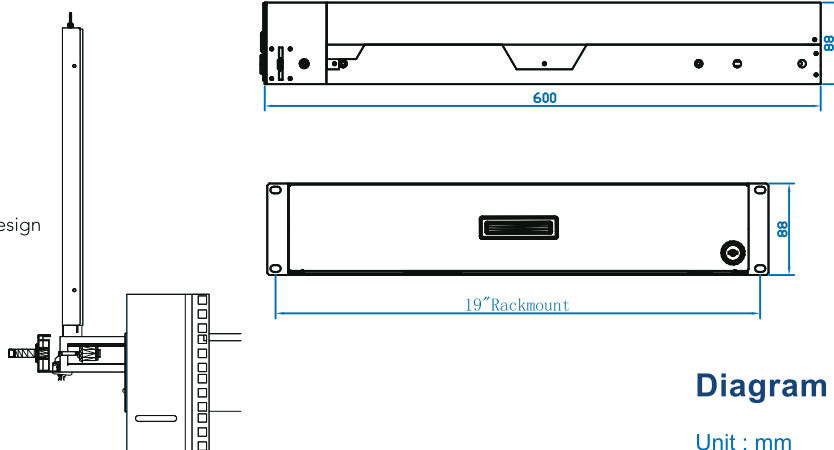

Diagram

Unit : mm

## Options:



AV Input



DVI Input



BNC Input



DC Power Input



Touch Screen

## Designed for:



## Drawer Features & Options

- 2U rackmount LCD drawer with a 20" SAMSUNG LCD
- Multi lingual on screen display menu
- AV Composite Video, S-Video, DVI and BNC input options
- 12, 24 and 48 volt DC power options

## LCD Drawer Benefits

- ▶ Ultra high resolution 1600 x 1200
- ▶ Sliding LCD allowing LCD to remain open when the rack door is closed

Monitor  Grade A industrial TFT LCD panel

- 20" 1600 x 1200 LCD with 300 nit brightness and 800:1 contrast ratio typical

## Ordering Information

Model	LCD2U20-011
-------	-------------

## Dimensions

Model	Product Dimension (W x D x H)	Net Weight
LCD2U20-011	442 x 600 x 88 mm 17.4 x 23.6 x 3.5 inch	14 kg / 31 lbs