


LCDK1020/1021 1U Rackmount Single Console USB DB-15 8/16 port KVM switch

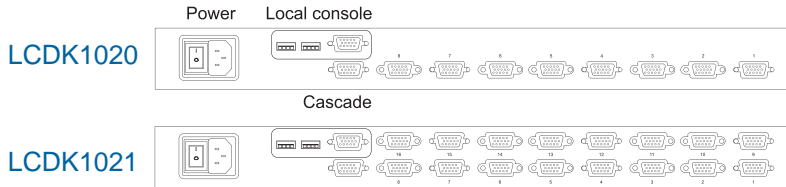

Designed for:



USB KVM Benefits

- ▶ 8 or 16 ports in 1U of rack space
- ▶ Support native SUN 1152 x 900 resolution
- ▶ Hot pluggable, no software or drivers required easy & quick installation

Technical Specification

- KVM Port**
 - Number of ports : 8 or 16
 - Connector : HDDB 15-pin
 - Connectivity : 2-in-1 KVM cable in 6 ,10 & 15 feet
- Console**
 - Graphic connector : HDDB15-pin VGA
 - Resolution : Up to 1920 x 1440
 - Bandwidth : 200MHz
 - Input device : 2 x USB type A for keyboard & mouse
- On Screen Display**
 - Port name : Up to 10 characters long
 - Port select : Front membrane button, Hotkey & On screen menu
 - Security : Support eight character password
 - Auto scan : 5~99 seconds
- Expansion** : Up to 128 servers by 8-level cascade
- Compatibility**
 - Multi-platform : Mix PCs, SUNs, IBMs, HPs, DELLs Server
 - Support : Windows Vista, 2003 / XP / 2000, Linux, Netware, Unix, DOS
- Power**
 - Input : 100 or 240V AC at 50 or 60 Hz via AC adapter
 - Option DC : 12V / 24V / 48V DC input
- Regulatory Approval** : FCC ,CE
- Environmental**
 - Operating : 0 to 50°C
 - Storage : -10 to 60°C
 - Relative humidity : 90%, non-condensing
 - Shock : 50G peak acceleration (11ms, half-sine wave)
 - Vibration : 58~100Hz / 0.98G (11min / cycle)

Accessories

LCD-A1014
LCD-A1015
LCD-A1016



USB 2-in-1 KVM cable
6ft, 10ft & 15ft available

LCD-A1019



6ft cascade cable

Dimensions

Model	Product Dimension (W x D x H)	Net Weight
LCDK1020	443 x 180 x 44 mm 17.4 x 7.1 x 1.73 inch	4 kg / 9 lbs
LCDK1021	443 x 180 x 44 mm 17.4 x 7.1 x 1.73 inch	4 kg / 9 lbs