



LCDK1038/1039 1U Rackmount 2 Console PS2 DB-15 8/16 port KVM switch over IP

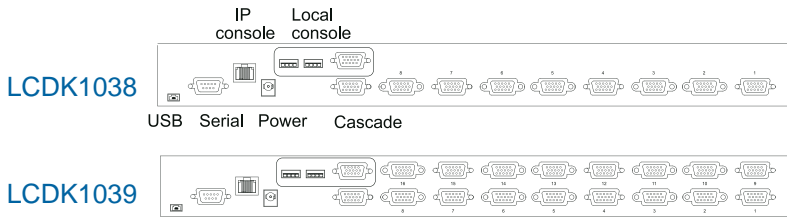

Designed for:

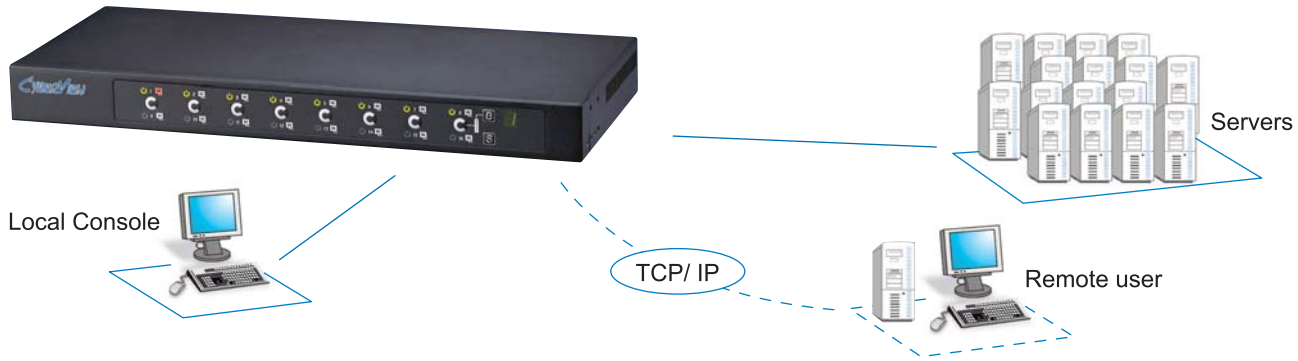

IP KVM Benefits

- ▶ 8 or 16 ports in 1U of rack space
- ▶ 128 bit secure browser based user access from anywhere in the world over IP
- ▶ Cost efficient remote server management between national / global sites

Technical Specification

- KVM Port**
 - Number of ports : 8 or 16
 - Connector : HDDDB 15-pin
 - Connectivity : 3-in-1 KVM cable in 6, 10, 15 & 33 feet
- Local Console**
 - Graphic connector : HDDDB 15-pin, VGA
 - Resolution : Up to 1920 x 1440
 - Input device : 2 x USB type A for keyboard & mouse
- IP Remote Console**
 - Connector : RJ45 ethernet
 - User management : 15-user login, 1 x active user
 - Network protocol : DHCP / BOOTP / DNS
 - Security : SSL v3, RSA, AES, HTTP / HTTPS, CSR
 - Resolution : 1600 x 1200
 - Browser : IE, Firefox, Safari, Netscape
 - Others : Serial port, virtual media via USB
- Compatibility**
 - Multi-platform : Mix PCs, SUNs, IBMs, HPs, DELLs Server
 - Support : Windows Vista, 2003 / XP / 2000, Linux, Netware, Unix, DOS
- Expansion** : Up to 128 servers by 8-level cascade
- Power**
 - Input : 100 or 240V AC at 50 or 60 Hz via AC adapter
 - Option DC : 12V / 24V / 48V DC input
- Regulatory Approval** : FCC, CE
- Environmental**
 - Operating : 0 to 50°C
 - Storage : -10 to 60°C
 - Relative humidity : 90%, non-condensing
 - Shock : 50G peak acceleration (11ms, half-sine wave)
 - Vibration : 58~100Hz / 0.98G (11min / cycle)

Accessories

LCD-A1004
LCD-A1005
LCD-A1006
LCD-A1007



PS/2 3-in-1 KVM cable
6ft, 10ft, 15ft & 33ft available

LCD-A1019



6ft cascade cable

LCD-A1001



PS/2 to SUN / USB adapter

Dimensions

Model	Product Dimension (W x D x H)	Net Weight
LCDK1038	443 x 180 x 44 mm 17.4 x 7.1 x 1.73 inch	4.5 kg / 10 lbs
LCDK1039	443 x 180 x 44 mm 17.4 x 7.1 x 1.73 inch	5 kg / 11 lbs