


LCDR8U20-04 20" WIDE LCD RACK MOUNT MONITOR



Synergy Global Technology Inc

www.RackmountMart.com

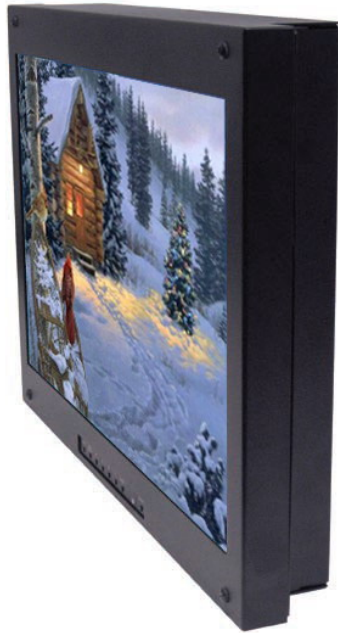

(Made in USA)

- Mounts in 8U of vertical rack space within 19" rack width.
- 20" Wide format TFT LCD display with 1680 x 1050 resolution.
- Fast video response time provides sharp text and crisp motion.
- 16:10 aspect ratio with wide H/V viewing angles (178°/178°).
- Steel front panel construction with a durable pant finish.
- Optional Video Inputs, Capacitive Touch Screen or Lexan. screen protection available.



GENERAL SPECIFICATIONS

Dimensions:

19.0" (W) x 14.0" (H) x 3.05" (D)

Weight:

15.0 lbs.

Power:

100 - 240 VAC, 50/60 Hz.
40 Watts max.

Plug & Play:

DDC2B

Temperature:

Operating: 10°C to 40°C
Storage: -20°C to 45°C

Humidity:

Operating: 10 to 80% RH (max)

Input Video Signals:

R.G.B. analog video, DVI (with HDCP)
Optional S-Video and Composite Video

Sync Type:

Seperate H/V, Composite H/V, SOG.

Input Connectors:

15 pin D-sub, DVI-D.

Colors Available:

Black.

Compatibility:

PC/Windows, Macintosh.

DISPLAY SPECIFICATIONS

Display Type:

a-si TFT/TN

Viewable Size:

20.1" Wide format.

Colors Displayed:

16.7 million colors.

Contrast Ratio:

800:1

Brightness:

300 cd/m² typ.

Viewing Angle (CR>5):

Horizontal: 178°

Vertical: 178°

Response Time:

12 ms (G to G)

Native Resolution:

VGA up to 1680 x 1050.

PIXEL Pitch

.258 MM.

Specifications subject to change without notice.

Contact us about other options and our additional rack mount products.