


RM1104-C Motherboard Spec

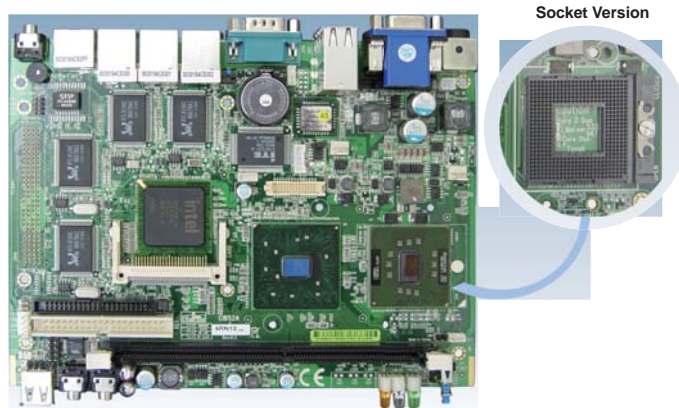

Specifications

. CPU type	Intel Celeron M 1GHz L2 0k CPU
. Front Side Bus	400 / 533 MHz
. MB Chipset	Intel 82852 GM / 82852 GME + ICH4
. BIOS	Award BIOS
. Graphics	Integrated with Intel 82852 GM / GME Shared system memory up to 64 MB
. LVDS	Data format of 18 bits / 36 bits
. Memory	1 x DDR SDRAM DIMM slot (max. 1GB)
. IDE	Ultra ATA 100/66/33, 1 x 40 pin 2.54mm, 1 x 44 pin 2.0mm CF Card Type II socket for ATA interface
. Audio	AC-Link for Audio CODEC, AC'97 2.1 Support Line-out / Mic-in / Line-in
. LAN	4 x Intel 82541PI 10 / 100 / 1000 Mbps
. IO Function	1 x RS232 IrDA 1.0 / ASKIR protocol, PS/2 keyboard & mouse
. USB	6 x USB 2.0 (4 external + 2 internal)
. DIO & WDT (option)	Hardware digital Input & Output, 4 x DI / 4 x DO Hardware Watch Dog Timer, 0~255 sec programmable
. Expansion interface	1 x Mini PCI socket 1 x PCI 104 (option)
. Power	On board DC +12V \pm 5% convert to +3.3V / +5V / +12V for system
. Dimension	200 x 150 mm
. Operation Temp.	0 ~ 60 °C
. Operation Humidity	5~95% @ 60 °C, non-condensing

Back Panel

