



Synergy Global Technology Inc

www.RackmountMart.com

Toll Free: 1-888-865-6888

Tel: 510-226-8368 Fax: 510-226-8968

Email: sales@RackmountMart.com

RM4022

4U Military Rackmount Chassis




INTRODUCTION


Ultra strong and compact for rugged environment and critical application. RM4022 is designed to perform military operations or industrial applications that require spill proof and high impact strength enclosure. Exceptional designed shock absorbing drive cage, cooling ventilation system, and total depth of 17.8 are the most versatile and tough rackmount chassis on the market.

FEATURES

- A Compact 4U Rackmount 17" Depth
- B 1.6mm Steel Body Chassis
- C Spill-proof Bezel with Lock
- D Shock Absorbing Drive Cage
- E Expansion Card Center Lock Crowbar
- F Front Access USB 2.0 x 1
- G 120mm x 1 Cooling Fan + Optional 80mm Blower x 1
- H Power and HDD LED
- I Power and Alarm Reset Switch
- J Removable Air Filter

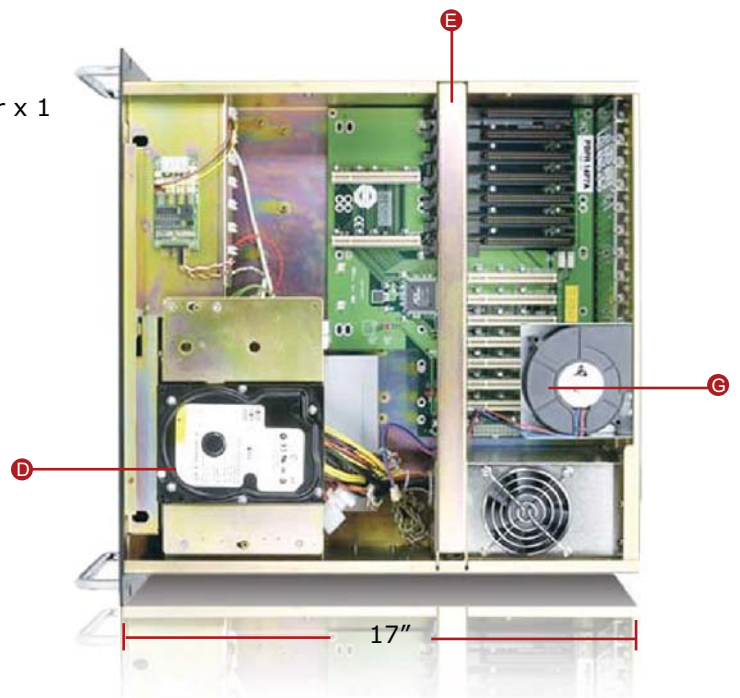

■ DRAWING

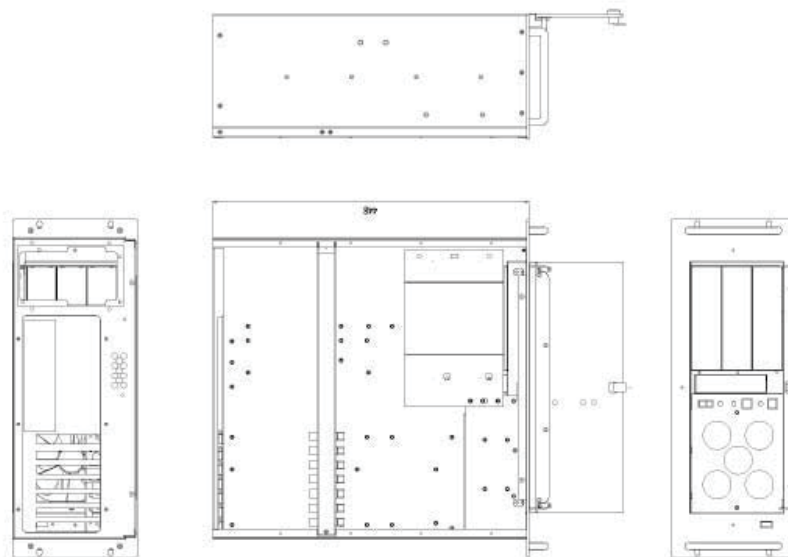

■ SPECIFICATIONS

Model Number	RM4022	Switches	Power ON/OFF, System & Alarm Reset
RoHS Compliance Version	Yes	Material of Front Bezel	Military Type -1.6mm SECC Zinc-Coated Steel
Standard Drive Bays	5.25" Drive: 3 3.5" Drive: 1 3.5" Drive [internal]: 1	Material of Handle	Military Type -1.6mm SECC Zinc-Coated Steel
Cooling Fan [Option]	1 x 120mm [1 x 80mm Blower]	Material of Main Chassis	Military Type -1.6mm SECC Zinc-Coated Steel
Mainboard Size [inch]	12 x 13	Color of Front Bezel	Black
Indicators	LEDs for Power ON/OFF, HDD, Fan & Alarm	Color of Main Chassis	Black
Speaker	0.4W Built-In	Front Connector	Front USB 2.0 x 1 Connector
Security	Front Bezel	Dimensions (WxHxD)	19 x 7 x 17.8 inch
Air Filter	Removable & Washable		