


Switched Rack PDU

Outlets. The Rack PDU has sixteen (16) NEMA 5-15 outlets.

Power cord. The 10-foot (3.05-meter) power cord terminates with a NEMA 5-15 plug.

Digital display. The digital display allows you to monitor the aggregate current of the Rack PDU and to establish a network connection using the network port.

AS-016-515-15A-515

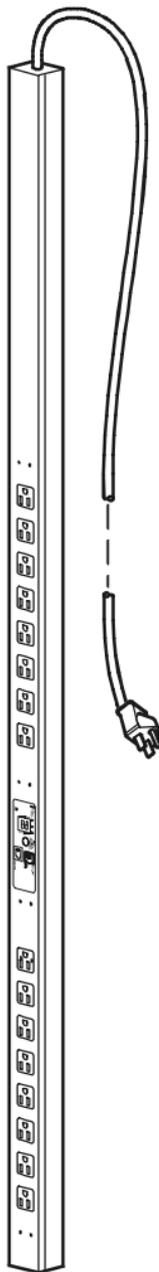

Specifications

Electrical

Input connector	NEMA 5-15 plug
Output connectors	(16) NEMA 5-15 outlets
Cord length	10 ft (3.05m)
Nominal input voltage	100/120VAC
Acceptable input voltage	± 10 % of nominal voltage
Input frequency	47–63 Hz

Physical

Dimensions (H × W × D)	49.00 × 2.19 × 1.73 in (124.46 × 5.56 × 4.39 cm)
Shipping dimensions (H × W × D)	84.00 × 6.00 × 5.00 in (213.36 × 15.24 × 12.70 cm)
Weight	9.50 lb (4.31 kg)

Environmental

Maximum elevation (above MSL)	
Operating	10,000 ft (3000 m)
Storage	50,000 ft (15 000 m)
Temperature	
Operating	23 to 113° F (–5 to 45° C)
Storage	–13 to 149° F (–25 to 65° C)
Humidity	
Operating	5 – 95%, non-condensing
Storage	5 – 95%, non-condensing

Compliance

EMC verification	FCC Part 15 Class A ICES-003, VCCI
Safety verification	UL/cUL Listed METI-DENAN
