



**Synergy Global Technology Inc**

[www.RackmountMart.com](http://www.RackmountMart.com)


## Switched Rack PDU

**Outlets.** The Rack PDU has twenty-four (24) NEMA 5-20 outlets.

**Power cord.** The 10-foot (3.05-meter) power cord terminates with a NEMA L21-20 plug.

**Digital display.** The digital display allows you to monitor the aggregate current of the Rack PDU and to establish a network connection using the network port.

**ASH-024-520-20A-L212-A**

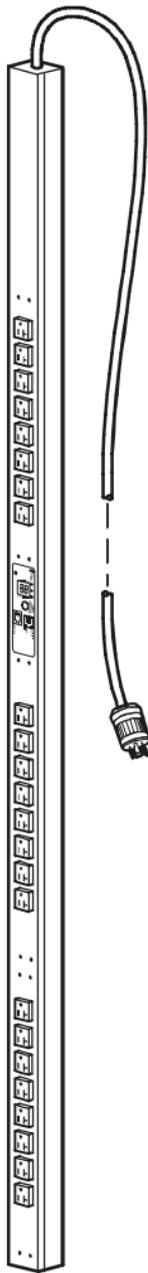

# Specifications

---

## Electrical

---

Input connector	NEMA L21-20 plug
Output connectors	(24) NEMA 5-20 outlets
Cord length	10 ft (3.05m)
Nominal input voltage	120/208 VAC
Acceptable input voltage	± 10 % of nominal voltage
Input frequency	47–63 Hz

---

## Physical

---

Dimensions (H × W × D)	63.75 × 2.19 × 1.73 in (161.92 × 5.56 × 4.39 cm)
Shipping dimensions (H × W × D)	83.00 × 4.50 × 6.00 in (210.82 × 11.43 × 15.24 cm)
Weight	13.00 lb (5.90 kg)

---

## Environmental

---

Maximum elevation (above MSL)	
Operating	10,000 ft (3000 m)
Storage	50,000 ft (15 000 m)
Temperature	
Operating	23 to 113° F (–5 to 45° C)
Storage	–13 to 149° F (–25 to 65° C)
Humidity	
Operating	5 – 95%, non-condensing
Storage	5 – 95%, non-condensing

---

## Compliance

---

EMC verification	FCC Part 15 Class A ICES-003
Safety verification	UL/cUL Listed

---