



Synergy Global Technology Inc

www.RackmountMart.com


Switched Rack PDU

Outlets. The Rack PDU has twenty-four (24) NEMA 5-20 outlets.

Power cord. The power cord connects the Rack PDU to one power source. The 3-foot (0.91-meter) cord terminates with a NEMA L21-20 plug.

Digital display. The digital display allows you to monitor the aggregate current of the Rack PDU and to establish a network connection using the network port.

ASH-024-520-20A-L212

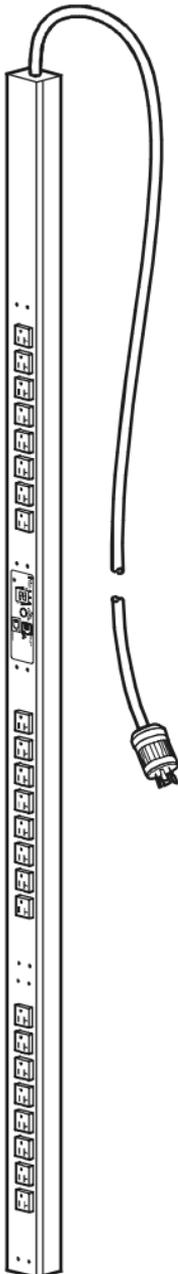

Specifications

Electrical

Input connector	NEMA L21-20 plug
Output connectors	(24) NEMA 5-20 outlets
Cord length	3 ft (0.91 m)
Nominal input voltage	120/208 VAC
Acceptable input voltage	± 10 % of nominal voltage
Input frequency	47–63 Hz

Physical

Dimensions (H × W × D)	63.75 × 2.19 × 1.73 in (161.92 × 5.56 × 4.39 cm)
Shipping dimensions (H × W × D)	83.00 × 4.50 × 6.00 in (210.82 × 11.43 × 15.24 cm)
Weight	13.00 lb (5.90 kg)

Environmental

Maximum elevation (above MSL)	
Operating	10,000 ft (3000 m)
Storage	50,000 ft (15 000 m)
Temperature	
Operating	23 to 113° F (–5 to 45° C)
Storage	–13 to 149° F (–25 to 65° C)
Humidity	
Operating	5 – 95%, non-condensing
Storage	5 – 95%, non-condensing

Compliance

EMC verification	FCC Part 15 Class A ICES-003
Safety verification	UL/cUL Listed
