



Short depth
440mm / 17.32"



Benefits

- ▶ 1U 17" LED-backlit LCD console drawer
- ▶ 1920 x 1080 native resolution / 16.7M colors (8-bit)
- ▶ HDMI 1.4 + VGA video input (speakers excluded)
- ▶ 104-key USB keyboard with touchpad
- ▶ One Man installation design
- ▶ Enhanced aesthetics with molded front handle and two point lock

Options

- Dual stereo speakers for HDMI
- DP 1.0 + Speakers
- DVI-D + Audio input & output + Speakers
- Composite + Audio IN + Speakers
- 3G / HD / SD-SDI Broadcast-grade input + Speakers
- DC power : 12V / 24V / 48V / 110V / 125V / 250V
- SUN Micro keyboard option

Product Specifications

Console Port

Video input	HDMI 1.4 + VGA
KB / MS	USB interface
VGA console 6ft cable	Drawer end : DB-15 + USB type A x 2
or	Server end : DB-15 + USB type A x 2
HDMI console 6ft cable	Drawer end : HDMI + USB type A x 2
	Server end : HDMI + USB type A x 2

LCD Panel

Panel size (diagonal)	17.3"
Native resolution	1920 x 1080
Brightness (cd/m ²)	300
Contrast ratio (typ.)	1000 : 1
Colors	16.7 M, 8-bit
Viewing angle (L/R/U/D)	85/85/85/85
Response time (ms)	25
Dot pitch (mm)	0.1989
Display area (mm)	381.888H x 214.812V
Surface treatment	Anti-glare, Hard-coating
Surface hardness	3H
Backlight type	LED
MTBF (hrs)	15,000

Physical

Product (W x D x H)	Single console	17.4 x 17.3 x 1.73 inch 442 x 440 x 44 mm
	Console w/ KVM	17.4 x 20.9 x 1.73 inch 442 x 530 x 44 mm
Net weight	Single console	23.8 lb / 10.8 kg
	Console w/ KVM	25.5 lb / 11.6 kg

* All dimensions stated are subject to change if options are selected / integrated to base model part codes

Mounting Distance

Single console drawer	470 ~ 700 mm 18.5 ~ 27.6 inch
Console w/ KVM drawer	470 ~ 800 mm 18.5 ~ 31.5 inch

Video Option

Digital	DVI-D	DVI-D single link
	Display port	DP 1.0 / HDCP 1.3
Analog	Composite (BNC)	NTSC & PAL

Audio Option

Input	Connector	3.5mm stereo jack
	Impedance / Power level	30kΩ / 750mV
Output	Connector	3.5mm stereo jack
	Resistance / Power level	30kΩ / 2.8V
Speaker	Dual stereo	2W x 2

Power

Input	Auto-sensing 100 to 240VAC, 50 / 60Hz	
Consumption (console / KVM)	Screen on	Max. 14W / Max. 45W
	Power saving mode	Max. 2W / Max. 34W
	Power button off	Max. 1W / Nil

Environment

Operating temp.	0 to 55°C degree
Storage temp.	-20 to 60°C degree
Operating humidity	10~90%, non-condensing
Storage humidity	5 ~90%, non-condensing
Operating altitude	16,000 ft
Non-operating altitude	40,000 ft
Shock	10G acceleration (11ms duration)
Vibration	10~300Hz 0.5G RMS random vibration

Compliance

EMC	FCC & CE
Safety	CE / LVD & UKCA
Environment	REACH & RoHS3 / WEEE

** Resolution related to LCD specification

2K KVM	IP	Remote	8-port
	0	0	-8HD

2K KVM Cable

LCD-A3011 (6 ft)
DVI-D KVM cableLCD-A3012 (6 ft)
HDMI KVM cable

Resolution 16:9 - max. 2560 x 1440
Support **: 16:10 - max. 1920 x 1200
4:3 - max. 1600 x 1200

DVI-D KVM	IP	Remote	12-port
	0	0	-12DVI

DVI-D USB KVM Cable

Resolution 16:10 - max. 1920 x 1200
Support **: 16:9 - max. 1920 x 1080
4:3 - max. 1600 x 1200

LCD-A3005 (6 ft)
LCD-A3006 (15 ft)

Cat6 Matrix KVM	IP	Remote	8-port	16-port	32-port
	1	1	-	-MU164IP2	-MU324IP2
	2	1	-	-MU163IP	-MU323IP
	0	1	-	-MU162	-MU322
	0	2	-	-MU163	-MU323
	0	3	-	-MU164	-MU324

Cat6 KVM Dongle

LCD-A2005
DP - USB dongleLCD-A2004
HDMI - USB dongleLCD-A2003
DVI - USB dongleLCD-A2001
VGA - USB dongleLCD-A2002
VGA - PS/2 dongle

Resolution 16:10 - max. 1920 x 1200
Support **: 16:9 - max. 1920 x 1080
4:3 - max. 1600 x 1200

** Resolution related to LCD specification

Cat6 Combo KVM	IP	Remote	8-port	16-port	32-port
	1	0	-U8KVM2IP	-U16KVM2IP	-U32KVM2IP
	0	1	-U8KVM2	-U16KVM2	-U32KVM2
	0	0	-U8KVM	-U16KVM	-U32KVM

DB-15 Combo KVM	IP	Remote	8-port	16-port
	1	0	-8KVM2IP	-16KVM2IP
	0	1	-8KVM2	-16KVM2
	0	0	-8KVM-u	-16KVM-u

DB-15 VGA USB KVM Cable



LCD-A1014 (6 ft)



LCD-A1015 (10 ft)



LCD-A1016 (15 ft)

Resolution 16:10 - max. 1920 x 1200
Support : 16:9 - max. 1920 x 1080
4:3 - max. 1600 x 1200

** Resolution related to LCD specification

IP Console



High Performance KVM Access Over IP

 



Connector : RJ45
User management : 1 x active user, 15-user login
Network protocol : DHCP / BOOTP / DNS
Security : TLS 1.3, AES, LDAP, Active Directory (AD), HTTP(s)
Browser : Chrome, Firefox, Edge, etc.
Resolution : 16:9 - max. 1920 x 1080 / 16:10 - max. 1920 x 1200 / 4:3 - max. 1600 x 1200

Standard Keyboard


N

keyboard integrated with touchpad

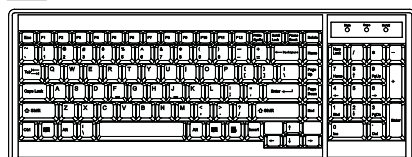

B

keyboard integrated with trackball

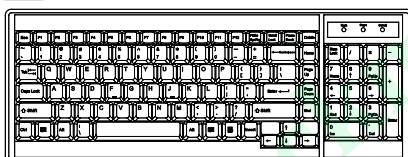

Supporting layouts

America



United States

United Kingdom



Germany



France



Spain



Norway

EMEA



Italy



Russia



Switzerland



Netherlands



Portugal

Asia



China



Japan



Korea



Arabia



Turkey

Keyboard Options

* US layout only

Mn

Mac keyboard with touchpad



Mac

Mb

Mac keyboard with trackball

Sn

SUN keyboard with touchpad

Sb

SUN keyboard with trackball



SOLARIS®