
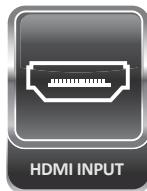


LCDR8U19-13 8U Tilttable Rack Mount 19" LCD with LED Backlight Display

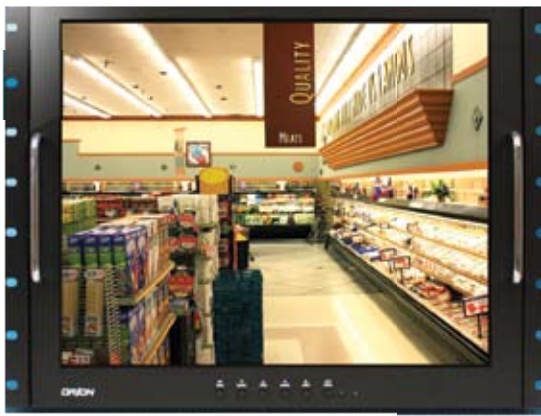

24 X 7 X 365

FEATURES

- » Industrial Electronic Galvanized Iron Cabinet
- » LED Backlight Unit
- » 1280 x 1024 @ 75Hz Resolution, 250 Nits, 1000:1 Contrast Ratio
- » BNC Video 2 In / 2 Out, S-Video 1 In, HDMI In 1 In, VGA 1 In, Audio 1 In, PC Stereo 1 In
- » 3D Motion Adaptive Deinterlacer / Noise Reduction
- » 1W x 2 Built-In Speakers
- » 8U Rack Mounting Form Factor



SPECIFICATIONS

Display	
Screen Size	19 Inch
Backlight Unit	LED BLU
Max. Resolution	1280 x 1024 @ 75Hz
Pixel Pitch	0.294 x 0.294mm
Brightness	250cd/m²
Contrast Ratio	1000 : 1
Aspect Ratio	5 : 4
Viewing Angle (H/V)	178° / 178°
Display Color	16.7 Million
Response Time	< 5ms
Video System	NTSC / PAL
Interface	
Video In / Out (BNC Type)	2 In / 2 Out
HDMI In	1 In
S-Video In	1 In
VGA In (15Pin D-Sub)	1 In
Audio In (RCA Type)	1 In
PC Stereo In	1 In
Transmitter	
Remote Control	Yes
Audio	
Built-in Speakers	Yes (1W x 2)
Features	
Filter Type	3D Motion Adaptive De-interlacer
Noise Reduction	Yes
Multi Language	English, Spanish, French, German, Italian
General	
Outline Dimension (W x H x D)	18.98" x 13.90" x 2.87"
Net Weight	5.8Kg (12.79 lbs)
Material / Color	Electronic galvanized iron / Black
Tilt Function	Yes
Consumption: < On	
AC100 ~ 240V(50/60Hz)	
Electrical Ratings	
DC12V / 3.5A	
Operating Temperature	
0° ~ 40° C / 32° ~ 104° F	
Storage Temperature	
-20° ~ 60° C / -4° ~ 140° F	
Mounts	
VESA™ Mount Size	100 x 100mm
Wall	SYWB-5, SYWB-10, SYWB-30, SYWB-31
Ceiling	SYCMK-01
Form Factor	8U Rack Mounting
Mount Type	Tilttable Rack Mount


*Design and specifications are subject to change without notice

TILT CAPABILITY


LCDR8U19-13 has flexible tilttable rack mount capability




INPUT INTERFACE

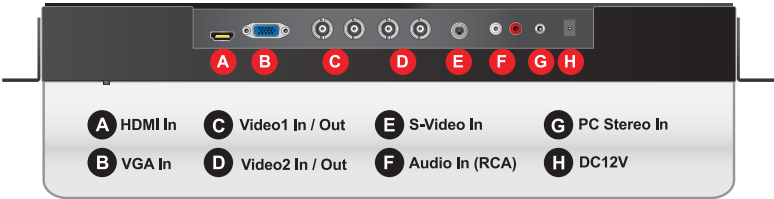

DIMENSIONS

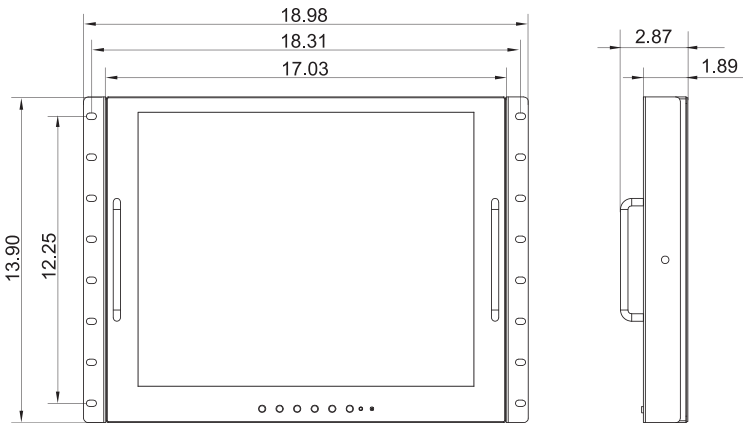

OTHER VIEW

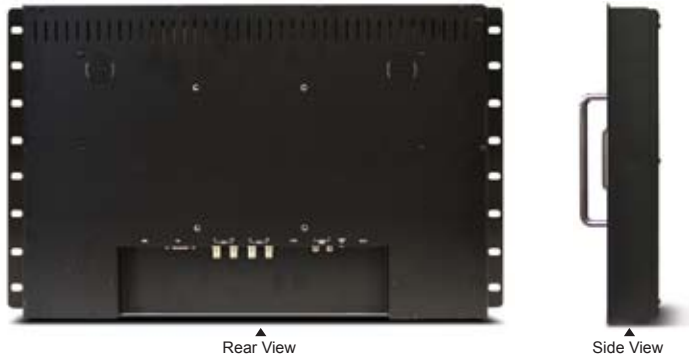

OPTIONAL MOUNTS

