


Diagrams ( mm )

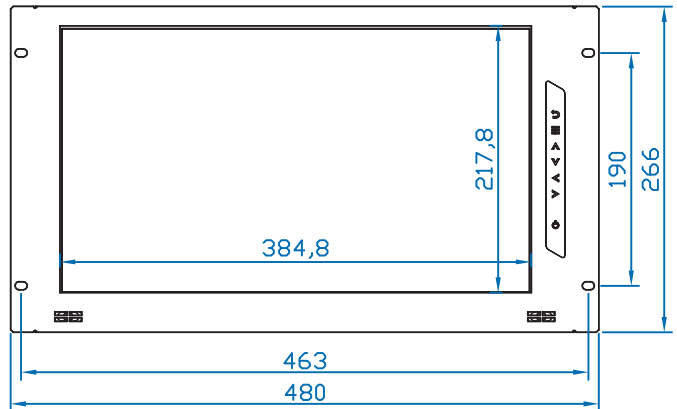

1080p  
Full HD

FC CE

\*\*\* Remote is optional \*\*\*



- Standard : DVI-D + VGA
- Ver.3.0 upgrade : DVI-D + VGA + HDMI + BNC + S-Video + audio
- Option : SDI, USB for touchscreen & DC power



I/O w/ TV option : HDMI, VGA, Composite, Audio  
TV w/ Remote controller

**Display Features & Benefits**

- ▶ 6U rackmount 17" widescreen LCD
- ▶ Support **Full HD** with 1080p resolution
- ▶ Green LED-backlit panel technology
- ▶ Ideal for CCTV security & industrial control
- ▶ Modern touch controls

**Options**

- 3G / HD / SD-SDI Broadcast-grade input
- MC Multi-display control solution
- 17" Touchscreen : Resistive
- S-Video + Composite ( BNC / RCA ), TV, HDMI or Audio input
- 48V, 24V or 12VDC power
- MIL-type or lockable connector
- Digital TV tuner decodes **ATSC** signal (w/ TV option)

**Specifications**

• **LCD Panel**

- Size (diagonal) : 17.3" widescreen TFT
- Max resolution : 1920 x 1080
- Brightness (cd/m2) : 400
- Backlight : LED
- Colors : 16.7 M, 8-bit
- Contrast ratio (typ) : 600 : 1
- Viewing angle (H/V) : 160° x 140°
- Active area (mm) : 382 x 215
- MTBF (hrs) : 50,000
- Signal input : VGA, DVI-D
- Signal input (w/ TV) : ATSC DTV / HDMI / VGA / Composite

• **Digital TV Tuner (Option)**

- Aerial input : 75 ohm coaxial, IEC type
- TV system : ATSC / NTSC

- **Sound** : 2 x 2W Power

• **Environmental**

- Operating : 0 to 50°C Degree
- Storage : -5 to 60°C Degree
- Relative humidity : 5~90%, non-condensing
- Shock : 10G acceleration ( 11 ms duration )
- Vibration : 5~500Hz 1G RMS random vibration

• **Casing Color** :

Black front panel ( RAL 9005 )

• **Regulatory** :

- Safety** : FCC & CE certified
- Environmental** : RoHS2 & REACH compliant

• **Power**

- Input : Auto-sensing 100 to 240VAC, 50 / 60Hz
- Consumption : Max. 48 Watt, Standby 5 Watt

• **Dimensions**

Product : 480 x 48 x 266 mm / 18.9 x 1.9 x 10.5 inch

• **Weight**

Net : 4.5 kgs / ( 9.9 lbs )