



Universal open frame mounting

Display Benefits

 
- ▶ 6.5" LCD with resolution 640 x 480
- ▶ Green LED-backlit panel technology
- ▶ Rugged construction against external impact

Options


- S-Video + BNC & Audio
- 6.5" Touchscreen : Capacitive, Resistive
- 48V, 24V or 12VDC power
- TV - Analog



Standard I/O



BNC-SPK upgrade I/O

 

Specifications

• **LCD Panel**

Manufacturer :	AUO
Size (diagonal) :	6.5" TFT
Max resolution :	640 x 480
Brightness (cd/m2) :	800
Backlight :	LED
Colors :	262 K
Contrast ratio (typ) :	600 : 1
Viewing angle (H/V) :	160° x 140°
Active area (mm) :	132 x 99
MTBF (hrs) :	50,000
Signal input :	VGA

• **Weight**

Net / Gross : 1.5 kgs (3.3 lbs)

• **Mounting :**

Universal mount / VESA mount

• **Environmental**

Operating :	0 to 50°C Degree
Storage :	-5 to 60°C Degree
Relative humidity :	5~90%, non-condensing
Shock :	10G acceleration (11 ms duration)
Vibration :	5~500Hz 1G RMS random vibration

• **Casing Color :**

Dark grey (RAL 7037)

• **Regulatory :**

FCC, CE


• **Power**

Input :	Auto-sensing 100 to 240VAC, 50 / 60Hz
Consumption :	Max. 40 Watt, Standby 5 Watt


• **Dimensions**

Product : 252 x 62 x 179 mm / 9.9 x 2.4 x 7 inch

Diagrams (mm)

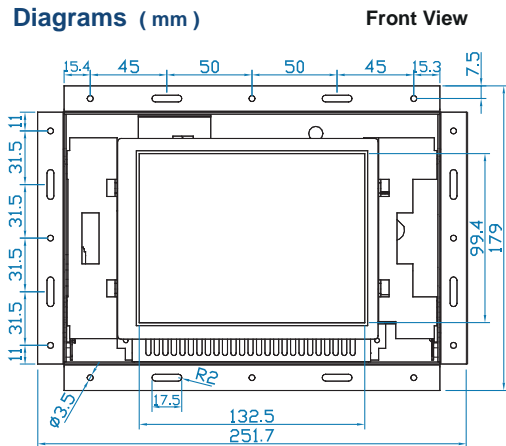

Side View

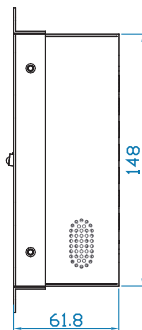

Rear View

