



Universal open frame mounting

**Display Benefits**

 
- ▶ 10.4" LCD with resolution 800 x 600
- ▶ Green LED-backlit panel technology
- ▶ Rugged construction against external impact

**Options**


- S-Video + BNC & Audio
- 10.4" Touchscreen : Capacitive, Resistive
- 48V, 24V or 12VDC power
- TV - Analog



**Standard I/O**



**BNC-SPK upgrade I/O**

 

**Specifications**

• **LCD Panel**

|                        |             |
|------------------------|-------------|
| Manufacturer :         | <b>AUO</b>  |
| Size (diagonal) :      | 10.4" TFT   |
| Max resolution :       | 800 x 600   |
| Brightness (cd/m2) :   | 230         |
| Backlight :            | LED         |
| Colors :               | 262 K       |
| Contrast ratio (typ) : | 500 : 1     |
| Viewing angle (H/V) :  | 160° x 130° |
| Active area (mm) :     | 211 x 158   |
| MTBF (hrs) :           | 30,000      |
| Signal input :         | VGA         |

• **Weight**

Net / Gross : 2.5 kgs ( 5.5 lbs )

• **Mounting :**

Universal mount / VESA mount

• **Environmental**

|                     |                                     |
|---------------------|-------------------------------------|
| Operating :         | 0 to 50°C Degree                    |
| Storage :           | -5 to 60°C Degree                   |
| Relative humidity : | 5~90%, non-condensing               |
| Shock :             | 10G acceleration ( 11 ms duration ) |
| Vibration :         | 5~500Hz 1G RMS random vibration     |

• **Casing Color :**

Dark grey ( RAL 7037 )

• **Regulatory :**

FCC, CE


• **Power**

|               |                                       |
|---------------|---------------------------------------|
| Input :       | Auto-sensing 100 to 240VAC, 50 / 60Hz |
| Consumption : | Max. 40 Watt, Standby 5 Watt          |


• **Dimensions**

Product : 282 x 57 x 219 mm / 11.1 x 2.2 x 8.6 inch

**Diagrams ( mm )**

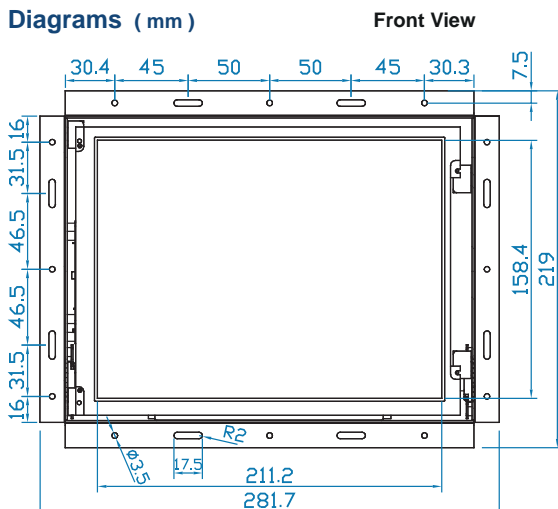

**Side View**

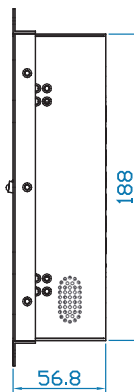

**Rear View**

