



LCD1U17-07 1U Rackmount Dual-Slide LCD Keyboard/KVM Drawer

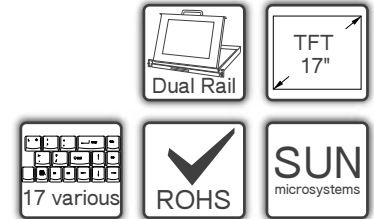

Features


- Dual Rail for independent Panel and Keyboard tray
- OSD function (On Screen Display) for LCD display
- Hidden handle for Keyboard tray
- Support Sun native resolution
- Support 17 various keyboard languages
- Bright Active Matrix TFT Display
- Durable keyboards (touchpad or trackball)
- Panel protected by tempered glass
- Audio Function (optional)
- DC power (optional)

Dimension

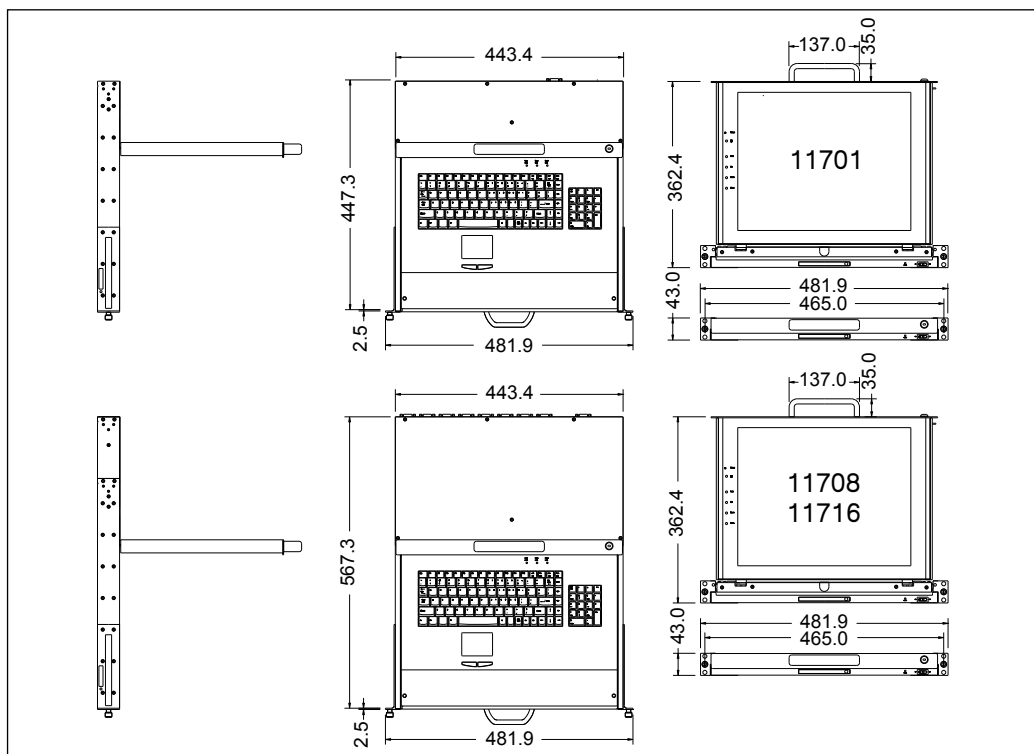

LCD1U17-07 1U Rackmount Dual-Slide LCD Keyboard/KVM Drawer

 Specification



Model Name	LCD1U17-07	LCD1U17-07-8KVM	LCD1U17-07-16KVM
Number of ports	1	8	16
Dimension	449.8x443.4x44 mm/17.7x17.5x1.7inches	569.8x443.4x44 mm/22.4x17.5x1.7 inches	569.8x443.4x44 mm/22.4x17.5x1.7 inches
Net Weight	12.0 Kg / 26.5 lbs	13.0 Kg / 28.7 lbs	13.5 Kg / 29.8 lbs
Display Size	17 inches		
Panel Type	Active Matrix TFT LCD		
Resolution Capabilities	Maximum Resolution up to 1280 x 1024 (SXGA)		
Pixel Pitch	Supports 0.264 mm x 0.264 mm		
Viewing Angle (CR>10)	Right-Left view 60°~70°(Typ) Up-Down View 45°~60°(Typ)		
Contrast Ratio	450 : 1		
Brightness	White 250 cd/m ² (Center 1 point Typ)		
Back Light	Four Lamps for Back Light		
Supported Colors	16.2M Colors (6-bit with FRC)		
Response Time	Rising Time 2 ms, Decay Time 14 ms		
Operating System	Dos, Windows (3.1, 9x, 2000, NT4, ME, XP, 2003 Server) Linux, Novell 3.12-6, HP UX, SUN		
Multi Platform	Support PS/2 and USB		
System Cables	VGA + PS/2 x 2 cable or VGA + USB x 1 cable		
Keyboard Mouse	106 key PS/2 keyboard with touch pad		
Sync	45 ~ 80 KHz		
Power Source	100 ~ 240 VAC input		
Power Consumption	25 W, 19.05 W for Panel		
Temperature	Operate 0° ~ 50°C / 32° ~ 122°F Storage -20° ~ 60°C / -4° ~ 140°F		
Humidity	10% ~ 90% RH		
Chassis Construction	Heavy duty steel materials		
Keyboard Language	US, UK, German, French, Spanish, Italian, Portuguese, Dutch, Swiss, Belgium, Swedish, Norwegian, Danish, Japanese, Mandarin, Russian, Hebrew		
Certification	CE / FCC, UL / CUL / C-Tick		

Ordering Optional

Color (Black / Beige / OEM color)

Cherry keyboard with trackball (PS/2 only)

Touch screen (USB or RS232)

DC power (- 48V ~ + 48V with additional cost / + - 12V without additional cost)

Additional SUN function key

DVI interface



Diagram

