




**USB Hub DB-15 Two Console KVM Benefits**

- ▶ VGA-USB DB-15 KVM with either 8 or 16 ports in 1U
- ▶ Remote access up to 150 meters
- ▶ 2 x USB 2.0 port sharing USB peripheral for computers
- ▶ Mix USB & SUN with Multi-Platform switch capability
- ▶ Support resolution up to 1920 x 1080
- ▶ SUN 1152 x 900 resolution compatible
- ▶ Cost efficient remote server management between user & equipment rooms
- ▶ Hot pluggable, no software or drivers required
- ▶ Easy & quick installation

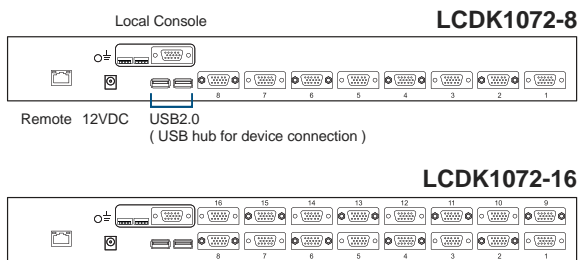

**Switch Features & Options**

- Multi lingual on screen display menu
- Advanced user profiles and configurable OSD hot key combinations
- DC power options : 12V / 24V / 48V / 110 ~ 125V

**Ordering Information**

Console	Local	Remote	IP	8-port	16-port
	1	1	0	<b>LCDK1072-8</b>	<b>LCDK1072-16</b>

**KVM Specification**

<p>■ <b>KVM Port</b></p> <p>Number of ports: 8 or 16</p> <p>Connector: DB-15 combo connector</p> <p>Connectivity: Combo 2-in-1 VGA + USB KVM cable, 6, 10 or 15 feet</p>	
<p>■ <b>Local Console</b></p> <p>Graphic Connector: 1 x DB-15</p> <p>Resolution: Up to 1920 x 1200</p> <p>Input device: 2 x USB type A for keyboard &amp; mouse</p> <p>USB hub: 2 x USB type A for sharing other peripheral devices among the computers</p>	
<p>■ <b>Remote Console</b></p> <p>Connector: 1 x DB 15-pin, VGA</p> <p>Resolution: Up to 1600 x 1200</p> <p>Input device: 2 x USB type A for keyboard &amp; mouse</p> <p>Remote I/O: RJ45 via Cat5 / Cat5e / Cat6 cable up to 150m</p> <p>Compensation: Auto adjust for cable length</p>	
<p>■ <b>Compatibility</b></p> <p>Hardware : HP / IBM / Dell PC, Server and Blade Server SUN / Mac</p> <p>OS Support : Windows / Linux / Unix / Mac OS</p>	

<p>■ <b>Power</b></p> <p>Input: Auto sensing 100 to 240VAC, 50 / 60 Hz</p> <p>Option DC: 12V / 24V / 48V / 110 ~ 125V DC input</p> <p>Consumption: Max. 12W</p>	
<p>■ <b>Regulatory</b></p> <p>Safety: FCC &amp; CE certified</p> <p>Environment: RoHS2 &amp; REACH compliant</p>	
<p>■ <b>Environmental</b></p> <p>Operating temperature : 0 to 55°C degree</p> <p>Storage temperature : -20 to 60°C degree</p> <p>Operating humidity : 20~90%, non-condensing</p> <p>Storage humidity : 5 ~90%, non-condensing</p> <p>Operating altitude : 16,000 ft</p> <p>Non-operating altitude : 40,000 ft</p> <p>Shock : 10G acceleration (11ms duration)</p> <p>Vibration : 5~500Hz 1G RMS random vibration</p>	
<p>■ <b>Product Information</b></p> <p>Dimension (W x D x H) : 443 x 171 x 44 mm / 17.4 x 6.7 x 1.73 inch</p> <p>Net weight : 3 kg / 6.5 lb</p>	

**KVM port connection**

LCD-A1014 / A1015 / A1016 USB KVM cable support USB server

USB Servers

DB-15 USB KVM port

**LCDA-A1014 / A1015 / A1016**

- 6 / 10 / 15 ft USB KVM cable
- Support USB server

**Remote & Local console connection**

Local USB console

Remote Cat6 console

CAT 5 / 6 cable max. 150m

Receiver

Remote USB console

Remote Console Resolution Support	Frequency ( Hz )
1600 x 1200	60
1440 x 900	60
1280 x 1024	60
1280 x 960	60
1152 x 864	75
1024 x 768	60 / 70 / 75

**Built-in USB Hub Usage & Connection**

2 x USB 2.0 ( USB hub for device connection )

Scanner

Printer

Camera

Flash Disk

Hard disk storage

Keyboard / Mouse

For detailed product specifications and options, please download the user manual from product page.