



Ultra short depth  
480mm / 18.9" only



**Product Specifications**

Console Port	
Video input	HDMI 2.0 + DP 1.2
KB / MS	USB interface
Console cable bundled	HDMI 2.0 cable x 1 + USB type A cable x 2

LCD Panel	
Panel size ( diagonal )	17.3"
Native resolution	3840 x 2160 @60Hz
Brightness ( cd/m <sup>2</sup> )	400
Contrast ratio ( typ. )	1000 : 1
Colors	16.7 M, 8-bit
Viewing angle ( L/R/U/D )	89/89/89/89
Response time ( ms )	16
Dot pitch ( mm )	0.0995
Display area ( mm )	382.12H x 214.94V
Surface treatment	Anti-glare
Surface hardness	3H
Backlight type	LED
MTBF ( hrs )	15,000

Physical	
Product ( W x D x H )	442 x 480 x 44 mm / 17.4 x 18.9 x 1.73 inch
Net weight	10.6 kg / 23.4 lb

\* All dimensions stated are subject to change if options are selected / integrated to base model part codes

**Benefits**

- ▶ 1U 17" LCD console drawer
- ▶ Dual slide - LCD and keyboard slide independently
- ▶ Ultra short depth 480mm / 18.9"
- ▶ 3840 x 2160@60Hz native resolution
- ▶ 2560 x 1440@60Hz QHD resolution support
- ▶ 1920 x 1080 & 1920 x 1200 resolution support
- ▶ 16.7M colors support ( 8-bit )
- ▶ HDMI 2.0 + DP 1.2 video input / USB KB / MS
- ▶ Dual stereo speakers for HDMI 2.0 & DP 1.2
- ▶ Ideal for open rack / short depth rack
- ▶ 104-key keyboard with touchpad
- ▶ One Man installation design
- ▶ Enhanced aesthetics with new molded front panel and 2-point lock

**Options**

- 3G / HD / SD-SDI Broadcast-grade input ( SDI )
- DC power : 12V / 24V / 48V / 110V / 125V / 250V
- SUN Micro keyboard available
- KVM integration

Mounting Distance	
Single console drawer	490 ~ 720 mm / 19.3 ~ 28.3 inch


Power		
Input	Auto-sensing 100 to 240VAC, 50 / 60Hz	
Consumption (console / KVM)	Screen on	Max. 21W / Max. 38W
	Power saving mode	Max. 2W / Max. 18W
	Power button off	Max. 1W / Nil

Environment	
Operating temp.	0 to 55°C degree
Storage temp.	-20 to 60°C degree
Operating humidity	10~90%, non-condensing
Storage humidity	5 ~90%, non-condensing
Operating altitude	16,000 ft
Non-operating altitude	40,000 ft
Shock	10G acceleration ( 11ms duration )
Vibration	10~300Hz 0.5G RMS random vibration

Compliance	
EMC	FCC & CE
Safety	CE / LVD & UKCA
Environment	REACH & RoHS3 / WEEE

**Standard Keyboard**

**N** keyboard with touchpad

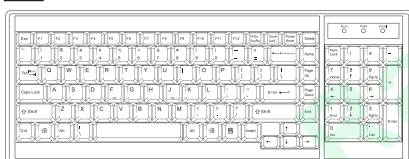

**Supporting layouts**

America	U.S.
EMEA	U.K.                        Germany                        France                        Russia                        Spain                        Italy
Asia	Japan                        Korea

**Keyboard Options**

\* US layout only



SUN keyboard with touchpad

