




**Synergy Global Technology Inc**

[www.RackmountMart.com](http://www.RackmountMart.com)

## Basic Rack PDU

**Outlets.** The Rack PDU has twenty-four (24) NEMA 5-20 outlets.

**Power cord.** The 10-foot (3.05-meter) power cord terminates with a NEMA L5-20 connector.

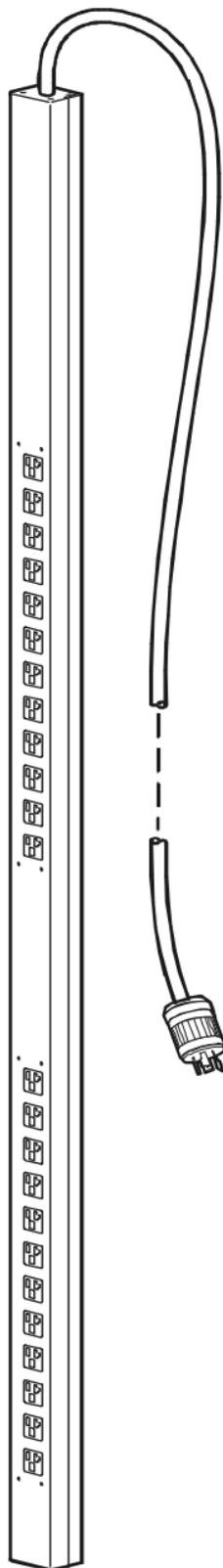

**RA5024-520-20A-L520**

# Specifications

---

## Electrical

---

Input connector	NEMA L5-20 plug
Output connectors	(24) NEMA 5-20 outlets
Nominal input voltage	120 VAC
Acceptable input voltage	± 10% of nominal voltage
Input frequency	50/60 Hz

---

## Physical

---

Dimensions (H × W × D)	63.75 x 2.19 x 1.73 in (161.92 x 5.56 x 4.39 cm)
Shipping dimensions (H × W × D)	84.00 x 6.00 x 5.00 in (213.36 x 15.24 x 12.7 cm)
Weight	10 lb (4.54 kg)

---

## Environmental

---

Maximum elevation (above MSL)	
Operating	15,000 ft (4500 m)
Storage	50,000 ft (15 000 m)
Temperature	
Operating	23 to 115° F (-5 to 45° C)
Storage	-13 to 149° F (-25 to 65° C)
Humidity	
Operating	5 – 95% RH non-condensing
Storage	5 – 95% RH non-condensing

---

## Compliance

---

Safety verification	UL/cUL 60950 Listed
---------------------	---------------------

---