


## Basic Rack PDU

**Outlets.** The Rack PDU has thirty (30) IEC-320-C13 outlets (15A maximum) and six (6) IEC-320-C19 outlets (16A maximum). APC power cord AP9877 (1.98 m; 6.5 ft) is available for purchase for use with C19 outlets.

**Input power cord.** The 3.05-m (10-ft) power cord terminates with a CS8365C connector.

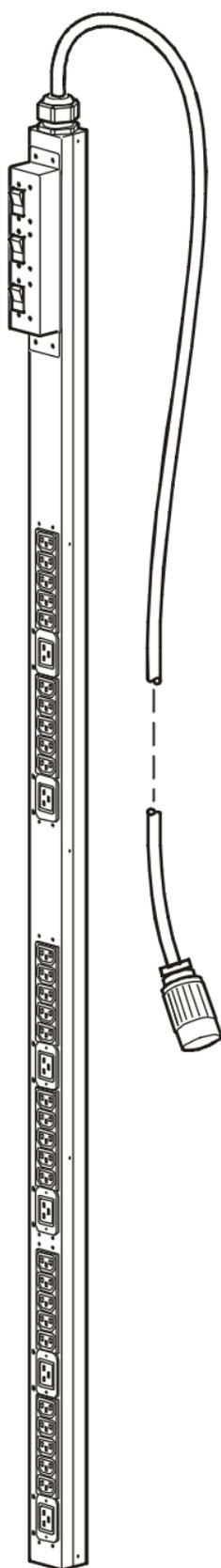

**RAH5036-C-35A-CS-A**

# Specifications

---

## Electrical

---

Input connector	CS8365C plug
Output connectors	(30) IEC-320-C13 (6) IEC-320-C19 outlets
Cord length	3.05 m (10 ft)
Nominal input voltage	200–240 VAC, 3-phase
Acceptable input voltage	+6%, –10% of nominal voltage
Input frequency	50/60 Hz
Output current	15A/C13, 16A/C19; 16A/bank
Overload protection	
Internal	(3) 20-A 2-pole breakers
External	(1) 50-A 3-pole breaker

---

## Physical

---

Dimensions (H × W × D)	177.80 × 5.58 × 4.45 cm (70.00 × 2.20 × 1.75 in)
<i>(Including breaker box)</i>	177.80 × 5.58 × 8.89 cm (70.00 × 2.20 × 3.50 in <sup>†</sup> )
Shipping dimensions (H × W × D)	210.82 × 15.24 × 12.70 cm (83.00 × 6.00 × 5.00 in)
Weight	8.76 kg (19.33 lb)

---

## Environmental

---

Maximum elevation (above MSL)	
Operating	3000 m (10,000 ft)
Storage	15 000 m (50,000 ft)
Temperature	
Operating	–5 to 45° C (23 to 115° F)
Storage	–25 to 65° C (–13 to 149° F)
Humidity	
Operating	5–95% RH non-condensing
Storage	5–95% RH non-condensing

---

## Regulatory Approvals

---

Product safety	UL, cUL Listed
----------------	----------------

---

<sup>†</sup> The depth with the breaker box (89 mm; 35.0 in) extends for only a part (191 mm; 7.50 in) of the height of the unit.