


## FIXED AND ADJUSTABLE VESA MOUNTS

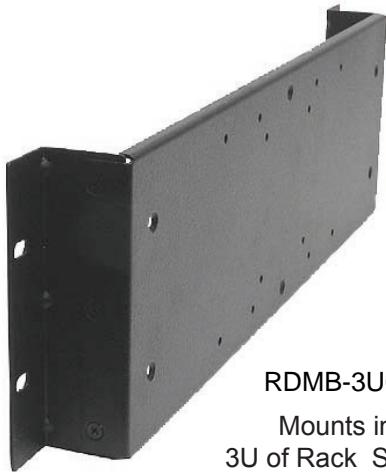

RDMB-3U01  
Mounts in  
3U of Rack Space


Fixed and adjustable rack mount brackets provide a stable platform for mounting VESA mount compatible monitors in EIA equipment racks.

The fixed mounting bracket RDMB-3U01 has VESA mount holes for **75x75 mm**, **100x100 mm** and **100x200 mm** monitors. The bracket mounts in 3U (5.25") of vertical rack space and positions the attached monitor 1.6" in front of rack mount rails. The bracket can also be supplied with an RDMS-4U01/4U02 shelf attached to allow use of space behind the monitor for additional equipment storage.

The adjustable mounting bracket RDMB-4U01 has VESA mount holes for **75x75 mm** and **100x100 mm** monitors. **100x200 mm** monitors can be mounted with an adapter plate. This bracket mounts in 4U (7.0") of vertical rack space and allows the attached monitor to be tilted in the down (or up) direction. The bracket in and out depth is also adjustable in 4 different increments. The bracket can also be supplied with an RDMS-4U01/4U02 shelf attached to allow use of space behind the monitor for additional equipment storage.



RDMB-4U01  
Mounts in  
4U of Rack Space

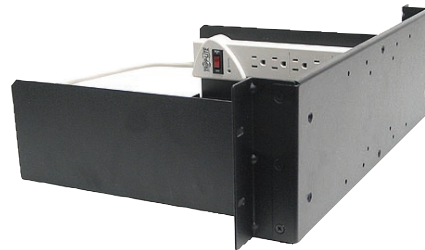

RDMB-3U01 with RDMS-4U02 Attached



RDMS-4U02  
RDMS-4U01 (without power strip)  
Attaches to RDMB-3U01 and RDMB-4U01



RDMB-4U01 with RDMS-4U02 Attached

We offer OEM and custom designs for your applications. Contact us for additional information.

