


LCDK1009/1010/1011 1U Rackmount Single User PS2 DB-15 4/8/16 port KVM switch



Local Console

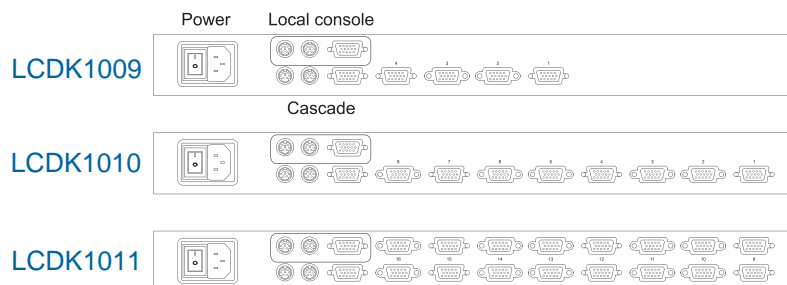

Designed for:



PS/2 KVM Benefits

- ▶ 4, 8 or 16 ports in 1U of rack space
- ▶ Low cost reliable PS/2 based server management
- ▶ No software or drivers required easy & quick installation

Technical Specification

- KVM Port**
 Number of ports : 4 or 8 or 16
 Connector : HDDB 15-pin
 Connectivity : 3-in-1 KVM cable in 6 ,10 & 15 feet
- Console**
 Graphic connector : HDDB15-pin VGA
 Resolution : Up to 1920 x 1440
 Bandwidth : 200MHz
 Input device : PS/2 mini-din 6-pin mouse
 PS/2 mini-din 6-pin keyboard
- On Screen Display**
 Port name : Up to 10 characters long
 Port select : Front membrane button, Hotkey & On screen menu
 Security : Support eight character password
 Auto scan : 5~99 seconds
- Expansion :** Up to 128 servers by 8-level cascade
- Compatibility**
 Multi-platform : Mix PCs, SUNs, IBMs, HPs, DELLs Server
 Support : Windows Vista, 2003 / XP / 2000, Linux, Netware, Unix, DOS
- Power**
 Input : 100 or 240V AC at 50 or 60 Hz via AC adapter
 Option DC : 12V / 24V / 48V DC input
- Regulatory Approval :** FCC ,CE
- Environmental**
 Operating : 0 to 50°C
 Storage : -10 to 60°C
 Relative humidity : 90%, non-condensing
 Shock : 50G peak acceleration (11ms, half-sine wave)
 Vibration : 58~100Hz / 0.98G (11min / cycle)

Accessories

LCD-A1004
LCD-A1005
LCD-A1006
LCD-A1007



PS/2 3-in-1 KVM cable
6ft, 10ft, 15ft & 33ft available

LCD-A1017
LCD-A1018



2ft & 6ft cascade cable

LCD-A1001



PS/2 to SUN / USB adapter

Dimensions

Model	Product Dimension (W x D x H)	Net Weight
LCDK1009	443 x 200 x 44 mm 17.4 x 7.9 x 1.73 inch	3.5 kg / 8 lbs
LCDK1010	443 x 180 x 44 mm 17.4 x 7.1 x 1.73 inch	3.5 kg / 8 lbs
LCDK1011	443 x 180 x 44 mm 17.4 x 7.1 x 1.73 inch	4 kg / 9 lbs