

# LCDR7U17-05 17" LCD RACK MOUNT MONITOR




**Synergy Global Technology Inc**

[www.RackmountMart.com](http://www.RackmountMart.com)



- 17" TFT LCD display (1280 x 1024 resolution) in only 7U (12.25") of rack space.
- Removable rack mounting brackets allow for additional mounting options.
- Housed in aluminum construction with a durable powder coat finish.
- Controls mounted on side of monitor for a clean appearance.
- Choice of light gray or black paint colors at no extra charge.
- Optional Lexan. (L) or 5 wire resistive touchscreen (T).

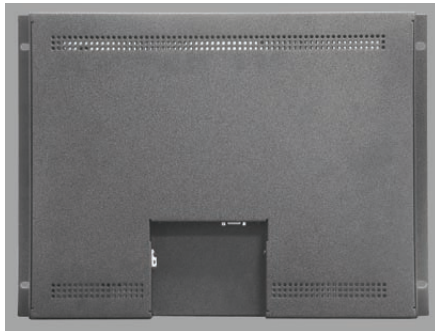

**Made in U.S.A.**

## GENERAL SPECIFICATIONS

### Dimensions:

22.0" (W) x 14.0" (H) x 2.8" (D)  
1.7" (D) = .75" in front of mounting rails  
.95" behind mounting rails.

### Weight:

8 lbs.

### Power:

100 - 240 VAC, 50/60 Hz.  
60 Watts max.

### Plug & Play:

DDC2B and DDC1

### Temperature:

Operating: 10°C to 40°C  
Storage: -20°C to 45°C

### Humidity:

Operating: 10 to 90% RH (max)

### Input Video Signals:

R.G.B. analog video, TTL H & V sync.

### Input Connectors:

Analog: 15-pin mini D-Sub.

### Colors Available:

Light Gray or Black (B).

### On-Screen Controls:

Brightness, Contrast, Horizontal & Vertical  
Position, Auto Adjust, OSD H & V Position, Input Select  
Color Temp., Reset.



## DISPLAY SPECIFICATIONS

### Display Type:

Active matrix TFT LCD

### Display area:

17" Diagonal.

### Colors Displayed:

16.7 million colors.

### Contrast Ratio:

1000:1

### Brightness:

280 cd/m<sup>2</sup> typ.

### Horizontal Frequency:

31 to 80 KHz.

### Vertical Frequency:

55 to 76 Hz.

### Viewing Angle (CR>5):

Horizontal: 160°

Vertical: 160°

### Response Time:

5 ms (G to G)

### Native Resolution:

VGA up to 1680 x 1050.

### Screen Protection:

Optional Lexan. (L) or

5 Wire Resistive

Touchscreen (T).

Specifications subject to change without notice.

Contact us about other options and our additional rack mount products.

[www.rackmountmart.com](http://www.rackmountmart.com)  
email : [sales@rackmountmart.com](mailto:sales@rackmountmart.com)

**SYNERGY GLOBAL TECHNOLOGY INC 1-888-865-6888**