


LCDR7U19-01 19" WIDE LCD RACK MOUNT MONITOR

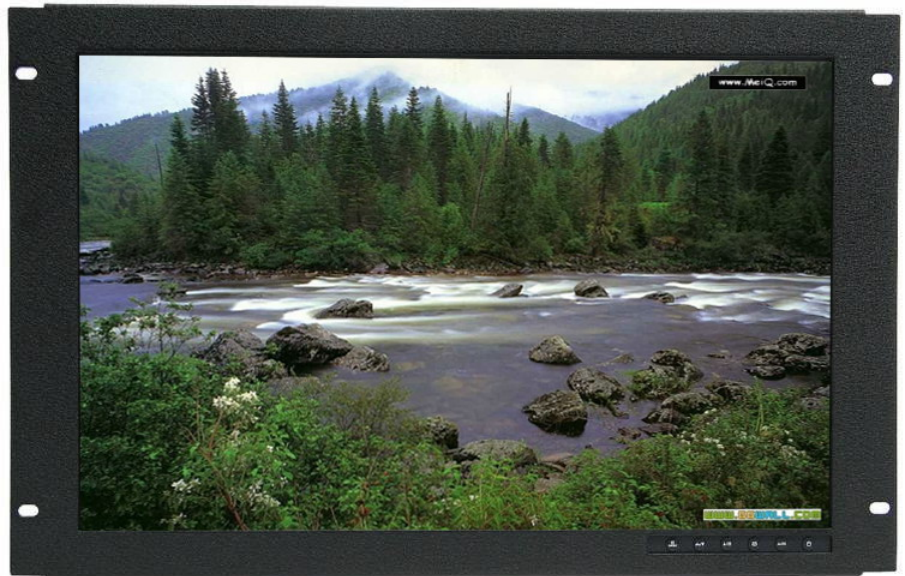

- Mounts in 7U of rack space.
- Wide format 16:10 aspect ratio.
- Fast 4 ms (G to G) response time.
- 19" TFT LCD display with 1440 x 900 resolution.
- Analog (ARGB) and Digital (DVI-D) input connectors.
- Steel front panel construction with a durable powder coat finish.



Made in U.S.A.

GENERAL SPECIFICATIONS

Dimensions:

19.0" (W) x 12.25" (H) x 3.0" (D)

Weight:

10.5 lbs.

Power:

100 - 240 VAC, 50/60 Hz.
42 Watts max.

On-Screen Controls:

Brightness, Contrast, Horizontal & Vertical
Position, Auto Adjust, OSD H & V Position, Input Select
Color Temp., Reset.

Plug & Play:

DDC2B

Temperature:

Operating: 10°C to 40°C
Storage: -20°C to 45°C

Humidity:

Operating: 10 to 80% RH (max)

Input Signal (VGA):

R.G.B. analog video, TTL H & V sync.

Input Signal (Digital):

DVI-D (TDMs).

Input Connectors:

Analog: 15-pin mini D-Sub.
Digital: 24 pin DVI-D.

Colors Available:

Black.

DISPLAY SPECIFICATIONS

Display Type:

Active matrix TFT LCD

Viewable Size:

19" Wide. format.

Colors Displayed:

16.2 million colors.

Contrast Ratio:

500:1

Brightness:

280 cd/m² typ.

Viewing Angle (CR>5):

Horizontal: 160°

Vertical: 160°

Response Time:

4 ms (G to G)

Native Resolution:

VGA Up to 1440 x 900.

PIXEL Pitch

0.285 mm.

MODEL NUMBER

LCDR7U19-01

LCDR7U19-01-Lex (with Lexan.)

Specifications subject to change without notice.

Contact us about other options and our additional rack mount products.

www.rackmountmart.com
email : sales@rackmountmart.com

SYNERGY GLOBAL TECHNOLOGY INC 1-888-865-6888