
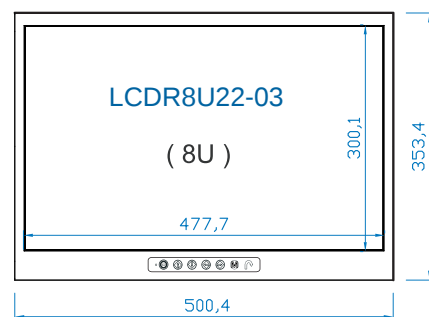


New

Diagram  
Unit : mm

## Options

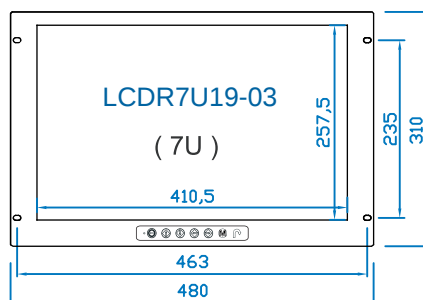

BNC + S-Video



Touch Screen



Quad Display



DC Power



NEMA 4



DVI-D



Audio

## LCD Display Benefits

- ▶ LED technology
- ▶ 800 cd/m<sup>2</sup> for 19" LCD, 600 cd/m<sup>2</sup> for 22" LCD
- ▶ Low power consumption
- ▶ Long lifetime up to 70,000 hours
- ▶ Minimum EMI emissions
- ▶ Operation temperature at -20°C
- ▶ High shock & vibration resistance
- ▶ Mercury free
- ▶ Slim size

## Optical Bonding Option



- 1mm thick optically clear adhesive for touchscreen or 4mm temper glass
- No air gap between the cover glass & LCD panel
- Increased LCD durability under vibration
- Eliminate residual and ghost images

## Anti-Reflective Film Option



- 0.1mm thick optical interference coating film
- Designed to provide visual enhancement
- Cost effective vacuum laminated technology
- Greatly reduced specular & diffuse reflection
- Increased contrast for improved readability
- Easy clean surface

## Ordering Information

Wide 19" LCD Series

Wide 22" LCD Series

| Model | LCDR7U19-03 | LCDR8U22-03 |
|-------|-------------|-------------|
|-------|-------------|-------------|

## Dimensions

| Model       | Product Dimension<br>(W x D x H)                  | Net Weight     |
|-------------|---------------------------------------------------|----------------|
| LCDR7U19-03 | 480 x 57.5 x 310 mm<br>18.9 x 2.3 x 12.2 inch     | 8 kg / 18 lbs  |
| LCDR8U22-03 | 500.4 x 59.1 x 353.4 mm<br>19.7 x 2.3 x 13.9 inch | 12 kg / 26 lbs |