

LCDR8U19-01 8U Rack mounted 19" TFT Monitor




Synergy Global Technology Inc

www.RackmountMart.com



- 8 rack units high (14.0").
- 19" active matrix TFT LCD display
- TFT surface protected by Lexan™ shield
- Attaches directly to a standard VGA card
- DVI-D digital signal input
- Wide viewing angle, high brightness and contrast

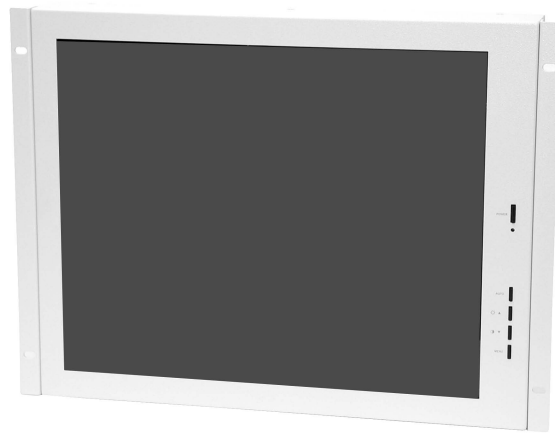

GENERAL SPECIFICATIONS

Dimensions:

19.0" (W) x 14.0" (H) x 2.5" (D)

Weight:

25 lbs.

Power:

100 - 240 VAC, 50/60 Hz.

60 Watts max.

Plug & Play:

DDC2B and DDC1

Temperature:

Operating: 0°C to 50°C

Storage: -20°C to 60°C

Humidity:

Operating: 10 to 85% RH (max)

Input Signal (VGA):

R.G.B. analog video, TTL H & V sync.

Input Signal (Digital):

DVI-D (TDMS).

Input Connectors:

Analog: 15-pin mini D-Sub.

Digital: 24 pin DVI-D.

Colors Available:

Light Gray or Black (B).

On-Screen Controls:

Brightness, Contrast, Horizontal & Vertical

Position, Auto Adjust, OSD H & V Position, Input Select

Color Temp., Reset.



DISPLAY SPECIFICATIONS

Display Type:

Active matrix TFT LCD

Display area:

19" Diagonal.

Colors Displayed:

16.7 million colors.

Contrast Ratio:

600:1

Brightness:

250 cd/m² typ.

Viewing Angle (CR>5):

Horizontal: 170°

Vertical: 170°

Response Time:

25 ms (G to G)

Native Resolution:

VGA up to 1280 x 1024.

Horizontal Frequency:

24 to 93 KHz.

Vertical Frequency:

55 to 85 Hz.

Specifications subject to change without notice.

Contact us about other options and our additional rack mount products.

www.rackmountmart.com
email : sales@rackmountmart.com

SYNERGY GLOBAL TECHNOLOGY INC 1-888-865-6888