

New



 
S-Video + BNC



Touchscreen - USB



DVI-D




Touchscreen - Serial



DC Power



 Audio



Options



BNC + S-Video



DVI-D



DC Power



Touch Screen



Audio



Quad Display



NEMA 4

Display Features & Options

- 8U LCD display with 22" widescreen LCD
- Quad Display Option
- Touchscreen option
- 12V, 24V and 48V DC power options
- AV + BNC, Audio and DVI-D options
- NEMA 4 and IP65 options for front protection

LCD Display Benefits

- ▶ 22" widescreen LCD with high resolution 1680 x 1050
- ▶ Ideal for CCTV security & industrial control

Monitor Grade A Wide 22" industrial TFT LCD panel

- 22" 1680 x 1050 LCD with 300 nit brightness and 1000:1 contrast ratio typical

Ordering Information


Model	LCDR8U22-02
-------	-------------

Dimensions

Model	Product Dimension (W x D x H)	Net Weight
LCDR8U22-02	500.4 x 59.1 x 353.4 mm 19.7 x 2.3 x 13.9 inch	12 kg / 26 lbs

Diagram

Unit : mm

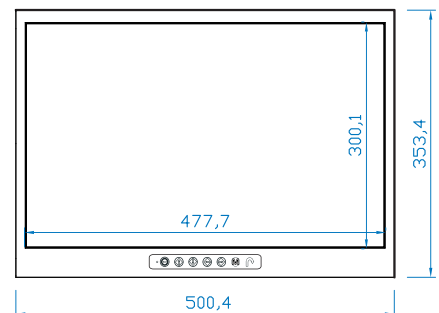

**** The rackmount width will be increased under Widescreen series.**

**** With Quad Display option, 1U height will be increased on the casing.**